

- Suitable for mounting and positioning GTC belt rollers and PTR sprockets

- Material:

Plated XC38 steel

304L stainless steel

steel or stainless steel

Accessories

- GTC belt tensioner (tome 4 p.146)


- PTR idler chain sprocket (tome 4 p.140)



Typical application using GTC belt roller



Typical application using PTR sprocket

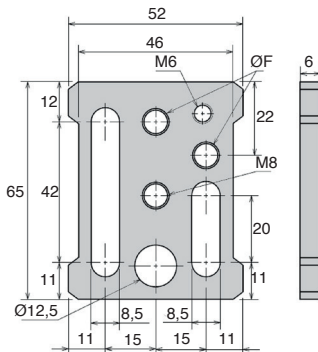

DISCOUNTS

| Qty | 1+ | 4+ | 10+ |
|-------|------|------|------------|
| Disc. | List | -10% | On request |

| Part number | Material | ØF | Stock* | Price each 1 to 3 |
|-------------|-----------------|-----|--------|-------------------|
| TMR-8 | Steel | M8 | ✓ | 25,97 € |
| TMR-10 | Steel | M10 | - | 25,97 € |
| TMR-8/SS | Stainless steel | M8 | - | 33,44 € |
| TMR-10/SS | Stainless steel | M10 | - | 33,44 € |



*Depending on availability - Dimensions in mm

- Suitable for mounting and positioning GTC belt rollers and PTR sprockets in a variety of positions
- Material:
Plated XC38 steel
304L stainless steel
- *Anti-rotation system



Accessories

- GTC belt tensioner (tome 4 p.146)
- PTR idler chain sprocket (tome 4 p.140)

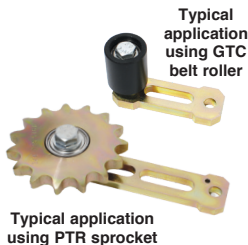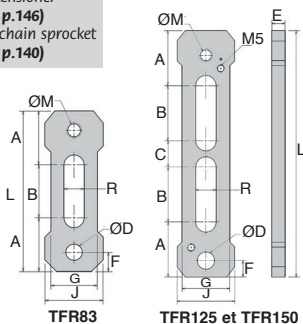

DISCOUNTS

| Qty | 1+ | 4+ | 10+ |
|-------|------|------|------------|
| Disc. | List | -10% | On request |

| Part number | A | B | C | ØD | E | F | G | J | L | ØM | R | Price each 1 to 3 |
|--------------------------------|------|------|----|------|---|----|----|----|------|-----|------|-------------------|
| Steel version | | | | | | | | | | | | |
| TFR83-8 | 28 | 27,5 | - | 8,5 | 8 | 10 | 24 | 30 | 83,5 | M8 | 10,5 | ✓ 14,77 € |
| TFR83-10 | 28 | 27,5 | - | 8,5 | 8 | 10 | 24 | 30 | 83,5 | M10 | 10,5 | - 15,22 € |
| TFR125-8 | 28 | 27,5 | 14 | 10,5 | 8 | 10 | 24 | 30 | 125 | M8 | 10,5 | ✓ 15,80 € |
| TFR125-10 | 28 | 27,5 | 14 | 10,5 | 8 | 10 | 24 | 30 | 125 | M10 | 10,5 | ✓ 16,40 € |
| TFR125-12 | 28 | 27,5 | 14 | 10,5 | 8 | 10 | 24 | 30 | 125 | M12 | 10,5 | ✓ 17,30 € |
| TFR150-12 | 33,5 | 33,5 | 16 | 12,5 | 8 | 15 | 29 | 35 | 150 | M12 | 12,5 | ✓ 25,38 € |
| TFR150-16 | 33,5 | 33,5 | 16 | 12,5 | 8 | 15 | 29 | 35 | 150 | M16 | 12,5 | - 26,27 € |
| Stainless steel version | | | | | | | | | | | | |
| TFR83-8/SS | 28 | 27,5 | - | 8,5 | 8 | 10 | 24 | 30 | 83,5 | M8 | 10,5 | - 23,28 € |
| TFR83-10/SS | 28 | 27,5 | - | 8,5 | 8 | 10 | 24 | 30 | 83,5 | M10 | 10,5 | - 24,19 € |
| TFR125-8/SS | 28 | 27,5 | 14 | 10,5 | 8 | 10 | 24 | 30 | 125 | M8 | 10,5 | - 29,28 € |
| TFR125-10/SS | 28 | 27,5 | 14 | 10,5 | 8 | 10 | 24 | 30 | 125 | M10 | 10,5 | - 30,15 € |
| TFR125-12/SS | 28 | 27,5 | 14 | 10,5 | 8 | 10 | 24 | 30 | 125 | M12 | 10,5 | - 32,26 € |
| TFR150-10/SS | 33,5 | 33,5 | 16 | 12,5 | 8 | 15 | 29 | 35 | 150 | M10 | 12,5 | - 45,11 € |
| TFR150-12/SS | 33,5 | 33,5 | 16 | 12,5 | 8 | 15 | 29 | 35 | 150 | M12 | 12,5 | - 45,72 € |
| TFR150-16/SS | 33,5 | 33,5 | 16 | 12,5 | 8 | 15 | 29 | 35 | 150 | M16 | 12,5 | - 47,21 € |

* Depending on availability - Dimensions in mm

Our other products



VT

Vari-Tork® slip friction clutch, 0.53 to 1.32 Nm



DILC

Indexing plunger with cam, with cam



 
EV

Stainless steel cable terminal, Threaded hole version



Q6

Deep groove ball bearing, Steel



ACL-PLAngle

Joining plate for aluminium profile, Angle connection



KKSS

Rounded end feather key, Stainless steel



CHB

Reaction arm, CHB gear reducers reaction arm



LRR-53

Spring loaded latch, Spring return latch - steel



BAC105

Storage bin, 8mm



BSCf

Knurled torque knobs - female, Knurled threaded torque



CHN_CHNSS

Straight long link stainless steel chain, Stainless steel



BPHR

Ball transfer unit housed spring loaded, High

Complementary products



PTR

Idler chain sprocket, For standard applications



GTC

Belt tensioner, For standard applications