

Rigid **manual** tensioner



TMR

Ideal for belts

- Suitable for mounting and positioning GTC belt rollers and PTR sprockets

- Material:

Plated XC38 steel

304L stainless steel


steel or
stainless steel



Typical application using
GTC belt roller



Typical application using
PTR sprocket

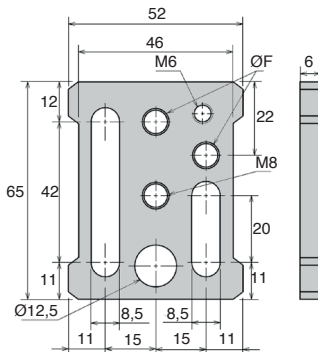

DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-10%	On request

Part number	Material	ØF	Stock*	Price each 1 to 3
TMR-8	Steel	M8	✓	25,23 €
TMR-10	Steel	M10	✓	25,23 €
TMR-8/SS	Stainless steel	M8	-	32,49 €
TMR-10/SS	Stainless steel	M10	-	32,49 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



CHA35
Hinge for aluminium profile, Hinge



PR85
Articulated foot Ø83, Ø 83



MBEX
Hexagonal ended handle, Hexagonal ended handle



RTN
BoWex® curved tooth gear coupling, Nylon



CQA30
Accessory for adjustment slide-system, 30



ADL_M
Male eye bolt conforms to DIN580, Steel



HTD5M_25
HTD Heavy duty timing pulley, HTD5 Steel



PTAF80-PAMF80
Articulated fixable foot with pressed base Ø80, Ø 80



LVT
Miniature motorised actuator 1A, 1 amper



SLBW
Indexing plunger, weldable, Weldable - Steel



PR125rehausse
Extension for articulated foot Ø123, articulated foot PR125



PNA
PERIFLEX® elastic coupling, Complete coupling

Complementary products



PTR
Idler chain sprocket, For standard applications



GTC
Belt tensioner, For standard applications