

# Rigid manual tensioner

Stock

## TMR

## Ideal for belts

- Suitable for mounting and positioning GTC belt rollers and PTR sprockets

- Material:

Plated XC38 steel

304L stainless steel


steel or  
stainless steel



Typical application using  
GTC belt roller



Typical application using  
PTR sprocket

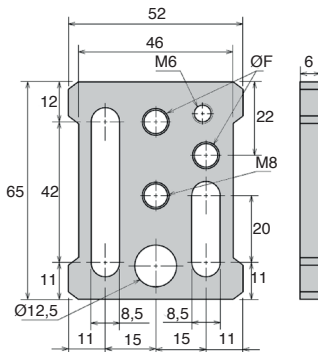

### DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-10%	On request

Part number	Material	ØF	Stock*	Price each 1 to 3
TMR-8	Steel	M8	✓	25,23 €
TMR-10	Steel	M10	✓	25,23 €
TMR-8/SS	Stainless steel	M8	-	32,49 €
TMR-10/SS	Stainless steel	M10	-	32,49 €

\*Depending on availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

 
Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



HTD5M\_25

HTD Heavy duty timing pulley, HTD5 Steel



RPP8

RPP heavy duty timing belt, RPP8



BGC

Oldham coupling, Clamp



DOMI80

Domino 80 adjustable slide, Slide DOMILINE 80



GLP

Small 6 lobe threaded handle - male, Technopolymer - Stainless steel



PR125rehausse

Extension for articulated foot Ø123, articulated foot PR125



RFVfp

Stainless steel worm and wheel gearboxes, Mounting bracket



CHM30

Worm and wheel gear reducer, up to 28 Nm



PRZ

Wear strip for slat top chain, Z profile to be clipped



AT5M AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane



PW\_PWG05

Worm - precision range, Stainless steel



SLBWSS

Indexing plunger, weldable, Weldable - Stainless steel

## Complementary products



PTR

Idler chain sprocket, For standard applications



GTC

Belt tensioner, For standard applications