

Short swivel head



TOC

Brass or stainless steel

- For guiding profile



- Materials:

Body: nickel brass or stainless steel

Nut/washer: stainless steel



stainless
steel
version

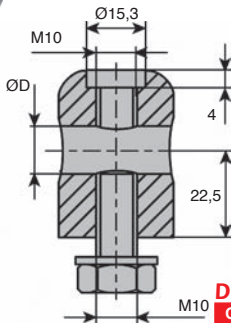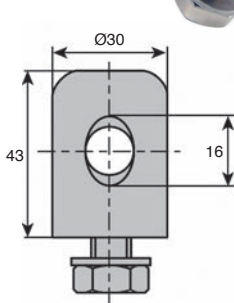

DISCOUNTS

Qty	1+	10+	20+
Disc.	List	-5%	On request

Part number	ØD	For Axis	Weight (kg)	Stock*	Price each 1 to 9
Nickel brass version					
TOC-12	12,5	APB12	0,18	✓	9,79 €
TOC-14	14,5	APB14	0,18	-	9,79 €
TOC-16	16,5	APB16	0,18	-	9,79 €
Stainless steel version					
TOC-12/SS	12,5	APB12	0,18	✓	16,06 €
TOC-14/SS	14,5	APB14	0,17	✓	15,79 €
TOC-16/SS	16,5	APB16	0,17	✓	15,79 €

*Depending on availability - Dimensions in mm

Our other products




CPAS
Stay with safety
catch, Opens upward



MDB_MTB
Moulded plastic bevel
gear (nylon), 2:1



ACLEPP
Right angled bracket
for aluminium profile,
4 holes

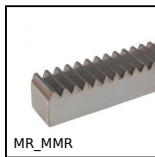

MR_MMR
Metric section rack,
Steel



PTKFss
Fixable foot for the
food industry,
Stainless steel - 3-A
standard



BPM
Slotted spring plunger
with ball tip, Stainless
steel 303



SBF
Sealed flange bearing
unit for Food Industry,
cover



CLG3
Moulded plastic spur
gear, Moulded plastic
(nylon)



MSP3815
Masterplate®
glueable insert



PTA40ssEB
Articulated foot with
sheet metal base



EX
Optional shaft for E-
type gear reducers, E



EIM
Stainless steel U bolt,
Stainless steel

Complementary products

tapped i...



RAG-12-M8
Roller guide
accessory, Anchoring
system



RAG
Roller guide,