

Short swivel head



TOC

Brass or stainless steel

- For guiding profile



- Materials:

Body: nickel brass or stainless steel

Nut/washer: stainless steel



stainless
steel
version

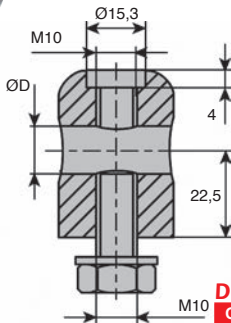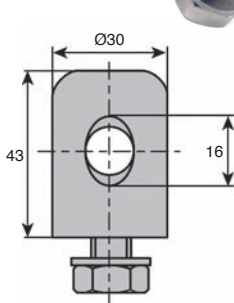

DISCOUNTS

Qty	1+	10+	20+
Disc.	List	-5%	On request


Part number	ØD	For Axis	Weight (kg)	Stock*	Price each 1 to 9
Nickel brass version					
TOC-12	12,5	APB12	0,18	✓	9,79 €
TOC-14	14,5	APB14	0,18	-	9,79 €
TOC-16	16,5	APB16	0,18	-	9,79 €
Stainless steel version					
TOC-12/SS	12,5	APB12	0,18	✓	16,06 €
TOC-14/SS	14,5	APB14	0,17	✓	15,79 €
TOC-16/SS	16,5	APB16	0,17	✓	15,79 €

*Depending on availability - Dimensions in mm

Our other products




VTLF
3 lobed handle,
Polyamide - Brass

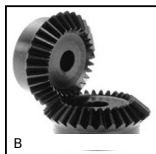

B
Steel bevel gear, 1:1



PRF_BR
Clamp for aluminium
profile, Clamp for
profile

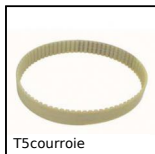

T5courrou
T type timing belt, T5
Steel cored
polyurethane



DIL
Lever operated
locking bolt, lever
clamp



PR125rehausse
Extension for
articulated foot Ø123,
articulated foot PR125



BABS303
303 Stainless steel
compact ball pin,
Stainless steel 303



HTD8M-BAR
HTD type tooth bar
stock, HTD8



BAP
Plastic clamping
collar, Ø10 - Ø20



HW_HT
Half-rail guide, Rail



GMK17_BR
Clamp for guiding
profile, Rounded only



PM3
Worm and wheel set,
Hardened steel

Complementary products



RAG-12-M8
Roller guide
accessory, Anchoring
system



RAG
Roller guide,