


- For guiding profile
- Materials:
Body: stainless steel 304
Nut/washer: stainless steel

stainless steel

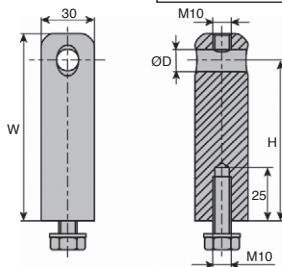

Typical application




DISCOUNTS

Qty.	1+	10+	20+
Disc.	List	-5%	On request

Part number	ØD	For Axis	H	W	Weight (kg)	Price each 1 to 9
TOL12-40/SS	12,5	APB12	40	55	0,28	27,48 €
TOL12-60/SS	12,5	APB12	60	75	0,38	33,57 €
TOL12-90/SS	12,5	APB12	90	105	0,55	36,86 €
TOL12-130/SS	12,5	APB12	130	145	0,77	49,17 €
TOL14-40/SS	14,5	APB14	40	56	0,28	49,17 €
TOL14-60/SS	14,5	APB14	60	76	0,38	27,48 €
TOL14-90/SS	14,5	APB14	90	106	0,55	31,79 €
TOL14-130/SS	14,5	APB14	130	146	0,77	35,09 €
TOL16-40/SS	16,5	APB16	40	57	0,28	49,17 €
TOL16-60/SS	16,5	APB16	60	77	0,38	27,48 €
TOL16-90/SS	16,5	APB16	90	107	0,55	36,86 €
TOL16-130/SS	16,5	APB16	130	147	0,77	49,17 €

*Depending on availability - Dimensions in mm

 Our other products



KSM

Cylindrical steel nut,
Steel - 1 thread



HCV

V- rail guidance
Simple Select®
system, on rail



VMS

Stainless steel knurled
thumb screw, Knurled



ACL

Joints for aluminium
profiles, Variable
angle corner



GARQT

Quarter turn lock pin
for clamping, Quarter
turn



DOMI80

Accessories, Clamping
lever



ATZY

Diabolo shaped elasto
mount, Steel



PSG35

Spur gear - precision
range, Stainless steel
316



G3-ECO

Eco range Spur gear,
Steel C45




PRF_JL6

Lip seal for panel,
Door seal - Ø 6mm



EBM

Steel U bolt, Steel

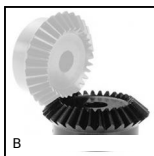

B

Steel bevel gear, 1:1

Complementary products



TOC

Short swivel head,
Short



APB_F

Adjusting rod for
clamp - Male,
Threaded



APB_T

Adjusting rod for
clamp - Female, Bored



RAG

Roller guide,