


- For guiding profile
- Materials:
Body: stainless steel 304
Nut/washer: stainless steel

stainless steel

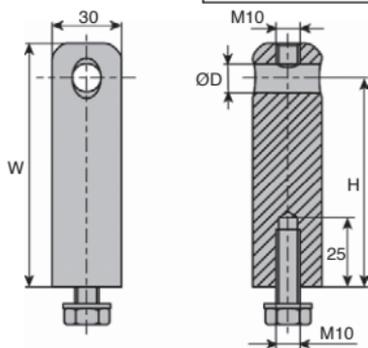

Typical application



DISCOUNTS

Qty.	1+	10+	20+
Disc.	List	-5%	On request

Part number	ØD	For Axis	H	W	Weight (kg)	Price each 1 to 9
TOL12-40/SS	12,5	APB12	40	55	0,28	27,48 €
TOL12-60/SS	12,5	APB12	60	75	0,38	33,57 €
TOL12-90/SS	12,5	APB12	90	105	0,55	36,86 €
TOL12-130/SS	12,5	APB12	130	145	0,77	49,17 €
TOL14-40/SS	14,5	APB14	40	56	0,28	49,17 €
TOL14-60/SS	14,5	APB14	60	76	0,38	27,48 €
TOL14-90/SS	14,5	APB14	90	106	0,55	31,79 €
TOL14-130/SS	14,5	APB14	130	146	0,77	35,09 €
TOL16-40/SS	16,5	APB16	40	57	0,28	49,17 €
TOL16-60/SS	16,5	APB16	60	77	0,38	27,48 €
TOL16-90/SS	16,5	APB16	90	107	0,55	36,86 €
TOL16-130/SS	16,5	APB16	130	147	0,77	49,17 €

*Depending on availability - Dimensions in mm

Our other products



RFKfp
Stainless steel gearbox - accessories, Mounting bracket



CLQassortiment
Assorted feeler strips, Assorted feeler strips



UCFL_SS
Stainless steel flanged bearing, Stainless steel



PSG255
Spur gear - precision range, Stainless steel 316



ARTE
Flexible bush, For multi-directional loads



MFB
Flexible bellows coupling, Aluminium and Bronze - With set screw



VDSCB
Sliding lock adjustment system, Blocking wedge for sliding lock for ...



BLHB20
Right angled gearbox, bored shafts, up to 1.77 Nm



PR40
Articulated foot Ø50, Ø 50



QNU
Single row cylindrical roller bearing, Free inner ring



PSG125
Spur gear - precision range, Case hardened steel 20NCD2



ZHGS
Plastic spur gear, Machined plastic (delrin)

Complementary products



TOC
Short swivel head, Short



APB_F
Adjusting rod for clamp - Male, Threaded



APB_T
Adjusting rod for clamp - Female, Bored



RAG
Roller guide,