


- For guiding profile
- Materials:
Body: stainless steel 304
Nut/washer: stainless steel

stainless steel

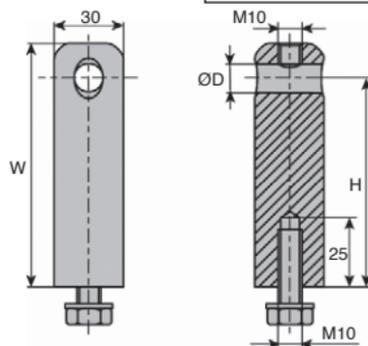

Typical application



DISCOUNTS

Qty.	1+	10+	20+
Disc.	List	-5%	On request

Part number	ØD	For Axis	H	W	Weight (kg)	Price each 1 to 9
TOL12-40/SS	12,5	APB12	40	55	0,28	27,48 €
TOL12-60/SS	12,5	APB12	60	75	0,38	33,57 €
TOL12-90/SS	12,5	APB12	90	105	0,55	36,86 €
TOL12-130/SS	12,5	APB12	130	145	0,77	49,17 €
TOL14-40/SS	14,5	APB14	40	56	0,28	49,17 €
TOL14-60/SS	14,5	APB14	60	76	0,38	27,48 €
TOL14-90/SS	14,5	APB14	90	106	0,55	31,79 €
TOL14-130/SS	14,5	APB14	130	146	0,77	35,09 €
TOL16-40/SS	16,5	APB16	40	57	0,28	49,17 €
TOL16-60/SS	16,5	APB16	60	77	0,38	27,48 €
TOL16-90/SS	16,5	APB16	90	107	0,55	36,86 €
TOL16-130/SS	16,5	APB16	130	147	0,77	49,17 €

*Depending on availability - Dimensions in mm

Our other products



CFS
Miniature cam follower, Miniature



BLHB60
Right angled gearbox, bored shafts, up to 70 Nm



BAPT
Hardened Stainless steel ball pin, Hardened stainless steel



DOMI30
Connecting kits, XZ linking kit



CLB_M
Die cast zinc clamping lever - female, Zamak



GPLso
Brush, silk



ECF
Well nut, Chloroprene elastomer



GAL22
Conveyor wheel, Zinc plated steel



NAST
Cam follower without axial guide, With



RPCpl
Swivel castor with plate, Steel -



PGNT
Thermoplastic T handle, With threaded



BAC105
Storage bin, 8mm

Complementary products



TOC
Short swivel head, Short



APB_F
Adjusting rod for clamp - Male, Threaded



APB_T
Adjusting rod for clamp - Female, Bored



RAG
Roller guide,