


- For guiding profile
- Materials:
Body: stainless steel 304
Nut/washer: stainless steel

stainless steel

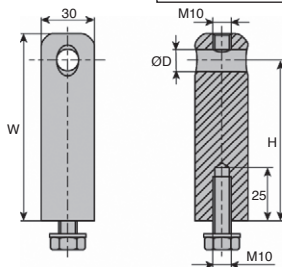

Typical application



DISCOUNTS

Qty.	1+	10+	20+
Disc.	List	-5%	On request

Part number	ØD	For Axis	H	W	Weight (kg)	Price each 1 to 9
TOL12-40/SS	12,5	APB12	40	55	0,28	27,48 €
TOL12-60/SS	12,5	APB12	60	75	0,38	33,57 €
TOL12-90/SS	12,5	APB12	90	105	0,55	36,86 €
TOL12-130/SS	12,5	APB12	130	145	0,77	49,17 €
TOL14-40/SS	14,5	APB14	40	56	0,28	49,17 €
TOL14-60/SS	14,5	APB14	60	76	0,38	27,48 €
TOL14-90/SS	14,5	APB14	90	106	0,55	31,79 €
TOL14-130/SS	14,5	APB14	130	146	0,77	35,09 €
TOL16-40/SS	16,5	APB16	40	57	0,28	49,17 €
TOL16-60/SS	16,5	APB16	60	77	0,38	27,48 €
TOL16-90/SS	16,5	APB16	90	107	0,55	36,86 €
TOL16-130/SS	16,5	APB16	130	147	0,77	49,17 €

*Depending on availability - Dimensions in mm

Our other products



BAReglable

Adjustable locking pin
hardened steel,
adjustable



CHMR90

Worm and wheel gear
reducer, up to 540
Nm




HTD14M_55

Heavy duty timing
pulley, HTD14 Steel




SVR15

Screwjack with
travelling nut, with
moving nut

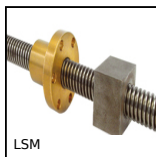

LSM

Stainless steel 316L
leadscrew, Stainless
steel - 1 thread

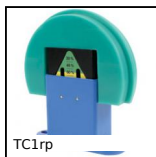

TC1rp

Automatic chain
tensioner, With 180°
guide



HTD14M_55

Heavy duty timing
pulley, HTD14 Cast



SH0

Parallel axis helical
gear, Steel 20NCD2



CLSCLP

Clevis components,
short version, Steel -
short range



IN1

Internal gear, Steel
20NCD2



ERT

Sliding nut, For T slot



SLVV|ok

Vertical toggle clamp,
Vertical toggle clamp /
vertical foot

Complementary products



RAG-12-M8

Roller guide
accessory, Anchoring
system



RAG

Roller guide,