

Swivel castor for aluminium profile

For loads up to 120kg

TPEPDB

- Swivel castor with brake for use with aluminium profile 40/45mm such as PRF4545
- Material:
 - Plate: powder-coated steel sheet, natural aluminium colour
 - Wheel: grey polypropylene (RAL 7001)

Advantages


- Silent
- Will not mark floor
- Low rolling resistance

Info

- Fixing screws not supplied (See PRF-ECL-M8 and BHC8/CHC8 screws)



Typical application

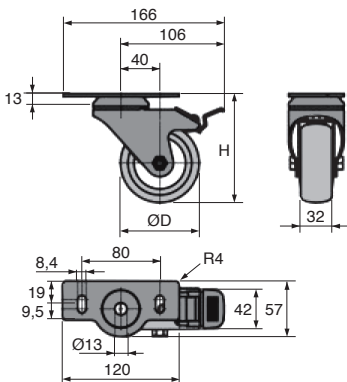

REMISES

Qté	1+	10+	30+
Rem. Prix		-5%	Sur demande

Part number	ØD	H	Maximum load (N)	Weight (g)	Price each 1 to 9
TPE80/PDB	80	111	1000	710	33,46 €
TPE100/PDB	100	136	1100	787	36,53 €
TPE125/PDB	125	161	1200	873	38,71 €

Dimensions in mm

Our other products



HTD5M-BAR

HTD type tooth bar stock, HTD5



PSG125

Spur gear - precision range, Pre-hardened Steel 35NCD6



KB_WW

Closed linear precision bearing, Economy range



YG4

HEAVY DUTY spur gear, Steel 35NCD6



EKONSL

Silicone conical elasto buffer, Female mounting



BKGS

Backlash free coupling Gerwah®, from 1.2 to 450Nm



QTR

Tapered roller bearing, Steel



CAP820

Slim slat top chain acetal, Narrow straight range 820



RFK48B

Hypoid gearbox - Stainless steel, up to



 
PLM-20SC

Threaded cylindrical magnet, With



SVT_CH

Screwjack - pivot mounting, Pivoting



LAT4

4A motorised linear actuator, 4 amperes

Complementary products



TPEF

Castor for aluminium profile, Fixed



PRF4545

Standard aluminium profile, 45 x 45 mm



PRF_ECL

Nut for aluminium profile, Steel square nut with tab



CHC

Socket headed screw, Steel class 12.19