

# Swivel castor for aluminium profile

For loads up to 120kg

TPE/PDB

- Swivel castor with brake for use with aluminium profile 40/45mm such as PRF4545
- Material:
  - Plate: powder-coated steel sheet, natural aluminium colour
  - Wheel: grey polypropylene (RAL 7001)

## Advantages


- Silent
- Will not mark floor
- Low rolling resistance

## Info

- Fixing screws not supplied (See PRF-ECL-M8 and BHC8/CHC8 screws)



Typical application

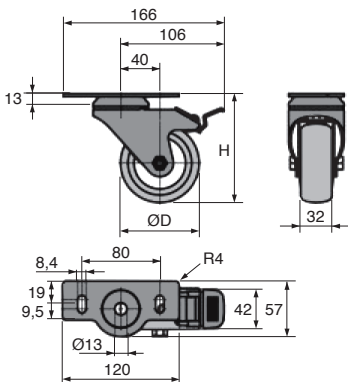

## REMISES

Qté	1+	10+	30+
Rem. Prix		-5%	Sur demande

Part number	ØD	H	Maximum load (N)	Weight (g)	Price each 1 to 9
TPE80/PDB	80	111	1000	710	33,46 €
TPE100/PDB	100	136	1100	787	36,53 €
TPE125/PDB	125	161	1200	873	38,71 €

Dimensions in mm

## Our other products



CHAFR

Adjustable friction hinges, Friction



BAG-MI

Split shaft collar with clamp lever, Steel



CHML40

Worm and wheel gear reducer, up to 57 Nm - Integrated torque limiter



CHT71

Asynchronous AC Motor, 0.18 to 0.55kW



CHCSS

Socket headed screw, Stainless steel - A2



CHAPAMss

Weld-on hinge with flat end, Stainless steel or Aluminium



M1

Worm and wheel set, Hardened steel



BUT

Panel stop, Panel stop



DB

Steel bevel gear, 2:1



TUBE25\_25

Square Tube, Aluminium or Stainless steel



RBGpl

Swivel castor with double brake, Steel - grey rubber



SHSS

Shoulder screw stainless steel 416, Pre-treated 416 stainless steel

## Complementary products



TPEF

Castor for aluminium profile, Fixed



PRF4545

Standard aluminium profile, 45 x 45 mm



PRF\_ECL

Nut for aluminium profile, Steel square nut with tab



CHC

Socket headed screw, Steel class 12.19