

High helix leadscrew

TPR

Travel of up to 40mm
per rotation

- Leadscrew only
- Right handed threaded
- For rapid adjustment applications as an alternative to using pneumatic systems or toothed drive belts
- No locking mechanism
- Material:
stainless steel 304

New sizes




Accessories

- Compatible with EPRC and EPRF
(No compatible with ECPR)

Info.

- Max length 3000mm
(Except TPR6.35: max.1000mm)

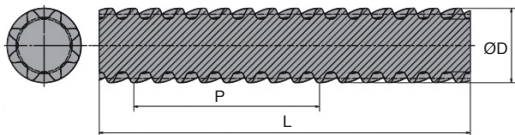

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØD	Pitch P (mm)	Pitch angle	Nombre of starts	Length L (mm)	Stock*	Price each 1 to 4
TPR6.35-2.54-1000/SS	6,35	2,54	7,26°	2	1000	-	41,00 €
TPR6.35-25.4-1000/SS	6,35	25,4	51,85°	8	1000	✓	43,52 €
TPR10-12-1000/SS	10	12	21,54°	4	1000	✓	72,55 €
TPR10-25-1000/SS	10	25	38,51°	8	1000	-	74,44 €
TPR10-50-1000/SS	10	50	57,86°	10	1000	-	97,15 €
TPR14-25-1000/SS	14	25	29,61°	5	1000	✓	107,24 €
TPR14-30-1000/SS	14	30	34,30°	6	1000	-	111,67 €
TPR18-40-1000/SS	18	40	35,65°	8	1000	✓	162,77 €

Dimensions in mm

Our other products



BLHM50

Right angled gearbox, double output shafts, up to 30 Nm



BLHB20

Right angled gearbox, bored shafts, up to 1.77 Nm



ZBconique

Machined plastic bevel gear, 1:1



SLVVlok

Vertical toggle clamp, Vertical toggle clamp / vertical foot



DB

Steel bevel gear, 2:1



AT5M AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane



PR821

Idle sprocket for slat top chain, Ranges 821 and 805



SH3

Parallel axis helical gear, Steel 20NCD2



VPSS

Small 6 lobe threaded handle - male, Duroplast - Stainless



CHMR110

Worm and wheel gear reducer, up to 980 Nm



BOX-TOR-H

 
Box set of Nitrile O-rings in nitrile, 3.00 x 2.00mm to 45.20 x



ACL

Joints for aluminium profiles, Variable angle corner

Complementary products



EPRF

High helix leadscrew, Flanged nut - up to 40mm per rotation



EPRC

High helix leadscrew, Cylindrical nut - up to 40mm per rotation