

High helix leadscrew

TPR

Travel of up to 40mm
per rotation

- Leadscrew only
- Right handed threaded
- For rapid adjustment applications as an alternative to using pneumatic systems or toothed drive belts
- No locking mechanism
- Material:
stainless steel 304

New sizes




Accessories

- Compatible with EPRC and EPRF
(No compatible with ECPR)

Info.

- Max length 3000mm
(Except TPR6.35: max.1000mm)

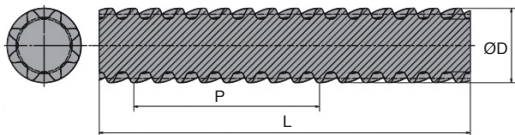

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØD	Pitch P (mm)	Pitch angle	Nombre of starts	Length L (mm)	Stock*	Price each 1 to 4
TPR6.35-2.54-1000/SS	6,35	2,54	7,26°	2	1000	-	41,00 €
TPR6.35-25.4-1000/SS	6,35	25,4	51,85°	8	1000	✓	43,52 €
TPR10-12-1000/SS	10	12	21,54°	4	1000	✓	72,55 €
TPR10-25-1000/SS	10	25	38,51°	8	1000	-	74,44 €
TPR10-50-1000/SS	10	50	57,86°	10	1000	-	97,15 €
TPR14-25-1000/SS	14	25	29,61°	5	1000	✓	107,24 €
TPR14-30-1000/SS	14	30	34,30°	6	1000	-	111,67 €
TPR18-40-1000/SS	18	40	35,65°	8	1000	✓	162,77 €

Dimensions in mm

Our other products




PTA100

Articulated levelling foot, pressed base Ø100, Ø 100



SHW

Plain washer, A2 Stainless steel

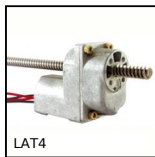


LAT4

4A motorised linear actuator, 4 amperes



YG2

 HEAVY DUTY spur gear, Steel 35NCD6



PF20NM

Worm and wheel gear reducer, up to 5 Nm



PSG35

Spur gear - precision range, Stainless steel 303



PGR

Folding revolving handle for handwheel, Folding



 
PW_PWG3

Worm - precision range, Stainless steel



VDS

Sliding lock adjustment system, Sliding lock for oblong



RPP5

RPP heavy duty timing belt, RPP5



PRES7HR

 
Manual workbench press, Force up to 700kg



NCT_AT

Variable angle connector, Variable angle

Complementary products



EPRF

High helix leadscrew, Flanged nut - up to 40mm per rotation



EPRC

High helix leadscrew, Cylindrical nut - up to 40mm per rotation