

# High helix leadscrew

TPR

Travel of up to 40mm  
per rotation

- Leadscrew only
- Right handed threaded
- For rapid adjustment applications as an alternative to using pneumatic systems or toothed drive belts
- No locking mechanism
- Material:  
stainless steel 304

New sizes




## Accessories

- Compatible with EPRC and EPRF  
(No compatible with ECPR)

## Info.

- Max length 3000mm  
(Except TPR6.35: max.1000mm)

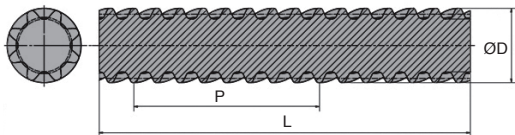

## DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØD	Pitch P (mm)	Pitch angle	Nombre of starts	Length L (mm)	Stock*	Price each 1 to 4
TPR6.35-2.54-1000/SS	6,35	2,54	7,26°	2	1000	-	41,00 €
TPR6.35-25.4-1000/SS	6,35	25,4	51,85°	8	1000	✓	43,52 €
TPR10-12-1000/SS	10	12	21,54°	4	1000	✓	72,55 €
TPR10-25-1000/SS	10	25	38,51°	8	1000	-	74,44 €
TPR10-50-1000/SS	10	50	57,86°	10	1000	-	97,15 €
TPR14-25-1000/SS	14	25	29,61°	5	1000	✓	107,24 €
TPR14-30-1000/SS	14	30	34,30°	6	1000	-	111,67 €
TPR18-40-1000/SS	18	40	35,65°	8	1000	✓	162,77 €

 
Dimensions in mm

## Our other products



GGP

Male wing knob,  
Technopolymer with  
brass spindle



RDE-W

Sealing washer  
Hygienic Usit®,  
Stainless steel - White  
EPDM



RFK38C

Hypoid gearbox -  
Stainless steel, up to  
200 Nm



SNG

Stainless/Polymer  
pillow block bearing,  
Cast iron - Split pillow



LVT

Miniature motorised  
actuator 4A, 4 ampers



DOMI120

Connecting kits, XZ  
linking kit



MDB\_MTB

Moulded plastic bevel  
gear (nylon), 2:1



PLB

Cylindrical spacer,  
Brass



BLHB40

Right angled gearbox,  
bored shafts, up to  
10.3 Nm



OPFL\_OPFM

Numerical counter  
accessories,  
Operating knob



DOMI80


Connecting kits, XZ  
linking kit



NCT

Square tube  
connector, Fixed  
angle

## Complementary products

 

EPRF

High helix leadscrew,  
Flanged nut - up to  
40mm per rotation



EPRC

High helix leadscrew,  
Cylindrical nut - up to  
40mm per rotation