

Round spur rack

Sta Stock


Module 0.25-1.5

Stainless steel

- Machined parts
- Pressure angle 20°
- Max. pitch error 1mm/300mm
- Material:
 - 304L stainless steel, except 0.25 module: 303 stainless steel

Options

- Other lengths are available

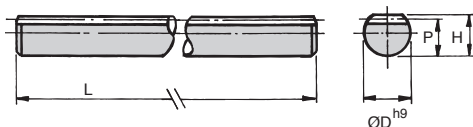

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Module	P (mm)	ØD (mm)	H (mm)	L (mm)	Stock*	Price each 1 to 5
TR0.25-400/303	0,25	5,30	6,00	5,55	400	✓	136,80 €
TR0.5-400/304L	0,50	8,70	10,00	9,20	400	✓	89,53 €
TR0.7-400/304L	0,70	9,80	12,00	10,50	400	✓	77,10 €
TR0.8-400/304L	0,80	9,70	12,00	10,50	400	✓	77,84 €
TR1-400/304L	1,00	9,50	12,00	10,50	400	✓	85,50 €
TR1.5-400/304L	1,50	16,00	20,00	17,50	400	✓	98,23 €

*Depending on availability - Dimensions in mm

Our other products



LC

Friction clutch, 190 to 1800 Nm



PR881

Idle sprocket for slat top chain, Range 881



BAC110

Swivel storage bin, Storage bin



CAP882

Flexible slat top chain acetal, Large range 882



PT821

Drive sprocket for slat top chain, Ranges 821 and 805



T5P_T10P

Connecting plate for T type timing belts, T10



CHA1056_U4

Screw-in hinge, Section 40X40



BLH30

Right angled gearbox, from 1.32 to 4.40 Nm



PRF_ROUL

Castor for aluminium profile, No brake



MEP

Revolving handle for handwheel, Fixed



HCSS

Set screw with hexagonal socket, Cup point



CNA-CNG

Right angled mounting plate, Right angled mounting plate for clevis

Complementary products



TRM

Spur round rack, Steel - module 1-6



TRMSS

Spur round rack, Stainless steel - module 1-5