

# Round spur rack

Sta Stock


## Module 0.25-1.5

Stainless steel

- Machined parts
- Pressure angle 20°
- Max. pitch error 1mm/300mm
- Material:
  - 304L stainless steel, except 0.25 module: 303 stainless steel

### Options

- Other lengths are available

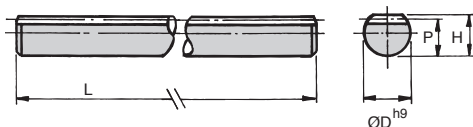

### DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Module	P (mm)	ØD (mm)	H (mm)	L (mm)	Stock*	Price each 1 to 5
TR0.25-400/303	0,25	5,30	6,00	5,55	400	✓	136,80 €
TR0.5-400/304L	0,50	8,70	10,00	9,20	400	✓	89,53 €
TR0.7-400/304L	0,70	9,80	12,00	10,50	400	✓	77,10 €
TR0.8-400/304L	0,80	9,70	12,00	10,50	400	✓	77,84 €
TR1-400/304L	1,00	9,50	12,00	10,50	400	✓	85,50 €
TR1.5-400/304L	1,50	16,00	20,00	17,50	400	✓	98,23 €

\*Depending on availability - Dimensions in mm

## Our other products



 
NPTR\_M  
Adjustable cross  
clamp, Adjustable



P30  
Worm and wheel gear  
reducer, up to 8.80  
Nm



RBNtc  
Swivel castor with  
central hole, Steel -  
rubber



M1  
Worm and wheel set,  
Machined plastic  
(delrin)



BPFL  
Sheet steel flanged  
bearing for light  
loads, Sheet steel



HK  
Manual locking clamp,  
Manual locking clamp  
T



NSB  
Standard linear  
bearing housing,  
Closed - Long



P55  
Worm and wheel gear  
reducer, up to 57 Nm



LBE  
Miniature closed  
linear bearing,



PCH  
Knob for gripping,  
Mushroom



CHT  
Asynchronous AC  
Motor 1.1 to 1.85kW,



CFS  
Miniature cam  
follower, Miniature

## Complementary products



TRM  
Spur round rack, Steel  
- module 1-6



TRMSS  
Spur round rack,  
Stainless steel -  
module 1-5