

# Round spur rack

Sta Stock


## Module 0.25-1.5

Stainless steel

- Machined parts
- Pressure angle 20°
- Max. pitch error 1mm/300mm
- Material:
  - 304L stainless steel, except 0.25 module: 303 stainless steel

### Options

- Other lengths are available

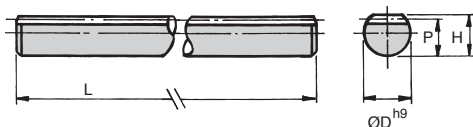

### DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Module	P (mm)	ØD (mm)	H (mm)	L (mm)	Stock*	Price each 1 to 5
TR0.25-400/303	0,25	5,30	6,00	5,55	400	✓	136,80 €
TR0.5-400/304L	0,50	8,70	10,00	9,20	400	✓	89,53 €
TR0.7-400/304L	0,70	9,80	12,00	10,50	400	✓	77,10 €
TR0.8-400/304L	0,80	9,70	12,00	10,50	400	✓	77,84 €
TR1-400/304L	1,00	9,50	12,00	10,50	400	✓	85,50 €
TR1.5-400/304L	1,50	16,00	20,00	17,50	400	✓	98,23 €

\*Depending on availability - Dimensions in mm


## Our other products



PTA150  
Articulated levelling foot, pressed base  
Ø150, Ø 150



 
CNA-CNG  
Right angled mounting plate, Right angled mounting plate for clevis



BLHM20  
Right angled gearbox, double output shafts, up to 1.77 Nm



 ZG1  
Plastic spur gear, Machined plastic (delrin)



M0  
Worm and wheel set, Machined plastic (delrin)



ZB  
Shaft for linear guides, Hardened ground stainless steel



DZYSS  
Stainless steel cylindrical stop, stainless steel



PCM  
Fixed cylindrical handle, Fixed non-turning handle



CTZYSS  
Stainless steel diablo shaped elasto mount, Stainless steel



BAG0  
Locking rings in steel, Steel



SHN  
Hexagonal nut DIN934, Steel (Class 6/8)



CLG2  
Moulded plastic spur gear, Moulded plastic (nylon)

## Complementary products



TRM  
Spur round rack, Steel - module 1-6



TRMSS  
Spur round rack, Stainless steel - module 1-5