

Round spur rack

Sta Stock


Module 0.25-1.5

Stainless steel

- Machined parts
- Pressure angle 20°
- Max. pitch error 1mm/300mm
- Material:
 - 304L stainless steel, except 0.25 module: 303 stainless steel

Options

- Other lengths are available

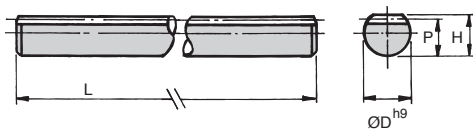

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Module	P (mm)	ØD (mm)	H (mm)	L (mm)	Stock*	Price each 1 to 5
TR0.25-400/303	0,25	5,30	6,00	5,55	400	✓	136,80 €
TR0.5-400/304L	0,50	8,70	10,00	9,20	400	✓	89,53 €
TR0.7-400/304L	0,70	9,80	12,00	10,50	400	✓	77,10 €
TR0.8-400/304L	0,80	9,70	12,00	10,50	400	✓	77,84 €
TR1-400/304L	1,00	9,50	12,00	10,50	400	✓	85,50 €
TR1.5-400/304L	1,50	16,00	20,00	17,50	400	✓	98,23 €

*Depending on availability - Dimensions in mm

Our other products



BPPL

Assembly tool for carrier ball, Mounting tool



LACT_SS

Adjustable Stainless steel cam lever, Male



PGM86-M5

Pull handle, Thermoplastic



CHTRP

Single and dual output gearboxes, Up to 34,5 Nm



BSM

Spring plunger with internal hexagonal socket, steel body, plastic pin



CHAR5050_Z

Spring hinge, screwed



MC

Self-compensating shock-absorber, Self-compensating - without adjust...



CHNrb

Warning chain with red and white links, Steel




SVR5

Screwjack with travelling nut, with



WING

 Manually tightened wing nut, Steel (ANSI



PF55

Worm and wheel gear reducer, up to 57 Nm



SSB

Stainless steel bevel gear, 1:1

Complementary products



TRM

Spur round rack, Steel - module 1-6



TRMSS

Spur round rack, Stainless steel - module 1-5