

Round spur rack

Sta Stock


Module 0.25-1.5

Stainless steel

- Machined parts
- Pressure angle 20°
- Max. pitch error 1mm/300mm
- Material:
 - 304L stainless steel, except 0.25 module: 303 stainless steel

Options

- Other lengths are available

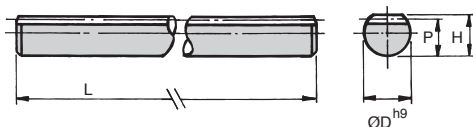

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Module	P (mm)	ØD (mm)	H (mm)	L (mm)	Stock*	Price each 1 to 5
TR0.25-400/303	0,25	5,30	6,00	5,55	400	✓	136,80 €
TR0.5-400/304L	0,50	8,70	10,00	9,20	400	✓	89,53 €
TR0.7-400/304L	0,70	9,80	12,00	10,50	400	✓	77,10 €
TR0.8-400/304L	0,80	9,70	12,00	10,50	400	✓	77,84 €
TR1-400/304L	1,00	9,50	12,00	10,50	400	✓	85,50 €
TR1.5-400/304L	1,50	16,00	20,00	17,50	400	✓	98,23 €


*Depending on availability - Dimensions in mm

Our other products



BLHB60

Right angled gearbox,
bored shafts, up to 70
Nm

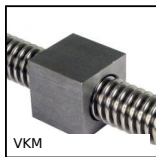

VKM

Square steel nut,
Steel - 1 thread




PRF45 GOU 3

Chute profile, Cable
cover



PM2

 Worm and wheel set,
Non hardened steel



M1

Worm and wheel set,
Machined plastic
(delrin)




BAC110

Swivel storage bin,
Adjustable support



TAC

Rigging screw
(hook/eye), Steel

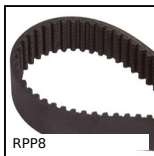

RPP8

RPP heavy duty
timing belt, RPP8



PGMram

Pull handle Hygienic
Usit®, Stainless steel



AT5M AT10M

AT type timing belt
per metre, AT10 Steel



SLBE

Indexing plunger -
Spacer, Spacer for



INO

Internal gear, Steel
20NCD2

Complementary products



TRM

Spur round rack, Steel
- module 1-6



TRMSS

Spur round rack,
Stainless steel -
module 1-5