
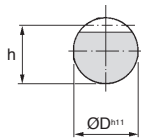
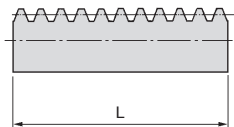


- Pressure angle 20°
- Diameter tolerance h11
- Material:
drawn steel A60

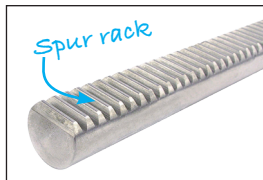

DISCOUNTS

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Module	h (mm)	ØD (mm)	L (mm)	Stock*	Price each 1 to 2
TRM1-1000	1	9,00	10	999	✓	96,77 €
TRM1.5-1000	1,5	13,50	15	999	✓	131,68 €
TRM2-1000	2	18,00	20	999	✓	132,83 €
TRM2.5-1000	2,5	22,50	25	997	✓	176,48 €
TRM3-1000	3	27,00	30	999	✓	168,88 €
TRM4-1000	4	36,00	40	1005	✓	204,94 €

*Depending on availability - Dimensions in mm

Our other products



RPCp1ss

Swivel castor with plate, Stainless steel - Polyamide



E50

Right angle helical reducers, from 3 to 41 Nm



 
PCS6ECO

Chain sprocket - steel, 6mm (DIN 04-1)



GLP

Small 6 lobe threaded handle - male, Technopolymer - Stainless steel




VKM

Square steel nut, Steel - 1 thread



TRMSS

Spur round rack, Stainless steel - module 1-5

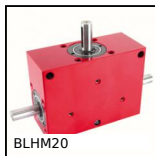

BLHM20

Right angled gearbox, double output shafts, up to 1.77 Nm



BCM_T

Driving collar, Driving collar



 
PML

Solid foot mount for heavy loads, Ø 100,



NIN

Self-locking nut, A2 Stainless steel



SBF


Open flange bearing unit for food industry,



ZBconique

Machined plastic bevel gear, 1:1

Complementary products

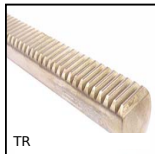


TR

Spur round rack, Stainless steel - module 0,25-1,5



TRMSS

Spur round rack, Stainless steel - module 1-5

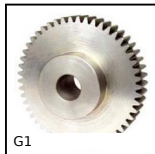

G1

Steel spur gear, Steel 20NCD2