
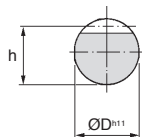
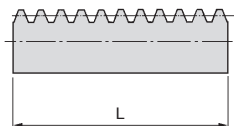


- Pressure angle 20°
- Diameter tolerance h11
- Material:
drawn steel A60

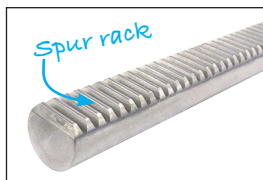

DISCOUNTS

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Module	h (mm)	ØD (mm)	L (mm)	Stock*	Price each 1 to 2
TRM1-1000	1	9,00	10	999	✓	96,77 €
TRM1.5-1000	1,5	13,50	15	999	✓	131,68 €
TRM2-1000	2	18,00	20	999	✓	132,83 €
TRM2.5-1000	2,5	22,50	25	997	✓	176,48 €
TRM3-1000	3	27,00	30	999	✓	168,88 €
TRM4-1000	4	36,00	40	1005	✓	204,94 €

*Depending on availability - Dimensions in mm

Our other products



BOX-CS

Hose clamp, Box set of steel hose clamps



PW_PWG2

Wheel - precision range, Bronze



PTRSS

Idler chain sprocket, For hostile environments



VTA

Vari-Tork® slip friction clutch, 0.53 to 1.32 Nm



BABpss

301 Stainless steel ball pin, Stainless steel



AFM

Flanged polymer bush, Food grade polymer



HW_HT

Half-rail guide, Wheel



VDSCB

Sliding lock adjustment system, Blocking wedge for sliding lock for ...



VLBS

Folding lifting ring for welding, Folding - for welding



PTA50ssEB

Articulated foot with sheet metal base Ø50, Articulated foot



CHNrb

Warning chain with red and white links, Steel



ZG1

Plastic spur gear, Machined plastic (delrin)

Complementary products



TR

Spur round rack, Stainless steel - module 0,25-1,5



TRMSS

Spur round rack, Stainless steel - module 1-5



G1

Steel spur gear, Steel 20NCD2