
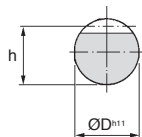
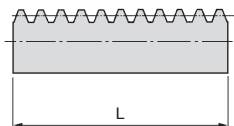


- Pressure angle 20°
- Diameter tolerance h11
- Material:
drawn steel A60

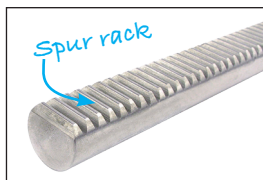


DISCOUNTS

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Module	h (mm)	ØD (mm)	L (mm)	Stock*	Price each 1 to 2
TRM1-1000	1	9,00	10	999	✓	96,77 €
TRM1.5-1000	1,5	13,50	15	999	✓	131,68 €
TRM2-1000	2	18,00	20	999	✓	132,83 €
TRM2.5-1000	2,5	22,50	25	997	✓	176,48 €
TRM3-1000	3	27,00	30	999	✓	168,88 €
TRM4-1000	4	36,00	40	1005	✓	204,94 €

*Depending on availability - Dimensions in mm

Our other products

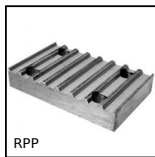

RPP

Connecting plate for RPP type timing belts, RRP5



PNA_R

PERIFLEX elastic coupling, Replacement tyre



H02SS

Needle roller universal joint - Stainless steel, Heavy duty DIN808-7...



PPJ

Indexing plunger with flange, With horizontal mounting flange and pu...



PRF_GAL

Roller for aluminium profile, Fixing kit for roller eccentric



CAP805

Slat top chain stainless steel, Large range 805



RHTplss

High Temperature Castor, up to 200kg



 
BAGtr

Lead screw clamping collar, Aluminium



ZDB

Machined plastic bevel gear , 2:1



GMK17_P

Flat Guide, Flat guide for conical profile



D-PAR_SS

 
Stainless steel progressive stop,



CFS

Miniature cam follower, Miniature

Complementary products




TR

Spur round rack, Stainless steel - module 0,25-1,5



TRMSS

Spur round rack, Stainless steel - module 1-5

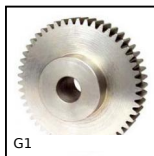

G1

Steel spur gear, Steel 20NCD2