
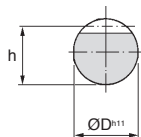
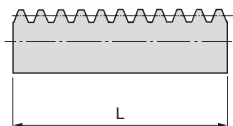


- Pressure angle 20°
- Diameter tolerance h11
- Material:
drawn steel A60

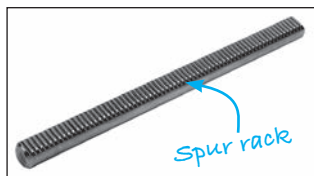


DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	Module	h (mm)	ØD (mm)	L (mm)	Stock*	Price each 1 to 5
TRM1-1000	1	9,00	10	999	✓	89,25 €
TRM1.5-1000	1,5	13,50	15	999	✓	121,45 €
TRM2-1000	2	18,00	20	999	✓	122,50 €
TRM2.5-1000	2,5	22,50	25	997	✓	162,75 €
TRM3-1000	3	27,00	30	999	✓	155,75 €
TRM4-1000	4	36,00	40	1005	✓	189,00 €
TRM5-1000	5	45,00	50	1005	-	287,00 €
TRM6-1000	6	54,00	60	999	-	301,00 €

*Depending on availability - Dimensions in mm

 Our other products




Roller for aluminium profile, Shaft support



Bevel gear - Steel C43, 3:1



 Linear bearing with inclined ball tracks, Standard loads / -20° +200°



Locking clips hook, 18mm



 
Telescopic slide rule, Fully extending



Single and dual output gearboxes, Up to 34,5 Nm



Box set of Nitrile O-rings, 18.00 x 2.00mm to 50.00 x 5.00



Manual lifting tables, For vertical strokes - Ø 20 mm column



Anti vibration mount, Steel



Threaded sleeves, Hexagonal - steel



Extra-thick die spring, Average



Wheel fixed with plate, Stainless steel - Polyamide

 
Complementary products



Round spur rack, Stainless steel - module 0,25-1,5



Round spur rack, Stainless steel - module 1-5



Spur gear, Steel 20NCD2