
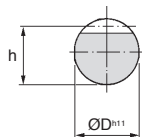
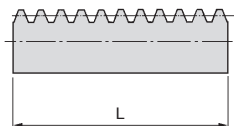


- Pressure angle 20°
- Diameter tolerance h11
- Material:
drawn steel A60

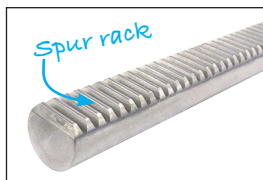

DISCOUNTS

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Module	h (mm)	ØD (mm)	L (mm)	Stock*	Price each 1 to 2
TRM1-1000	1	9,00	10	999	✓	96,77 €
TRM1.5-1000	1,5	13,50	15	999	✓	131,68 €
TRM2-1000	2	18,00	20	999	✓	132,83 €
TRM2.5-1000	2,5	22,50	25	997	✓	176,48 €
TRM3-1000	3	27,00	30	999	✓	168,88 €
TRM4-1000	4	36,00	40	1005	✓	204,94 €

*Depending on availability - Dimensions in mm

Our other products



MEP
Revolving handle for handwheel, Fixed



PLS
Cylindrical spacer, Stainless steel 303



BOX-TOR-INCH
Box set of Nitrile O-rings in inch NBR90Sh A, For fasteners and fittings...



TOC
Short swivel head, Short



ACLEPP
Right angled bracket for aluminium profile, 2 holes



BPPE
Ball transfer unit push fit, Light



AT10courroie
AT type timing belt, AT10 Steel cored polyurethane



ACLERP
Roller block for aluminium profile, With guide rail



TRM
Spur round rack, Steel - module 1-6



PAL
Self locking counter nut, For axial locking

 


PSG1
Spur gear - precision range, Case hardened



WS20
Drylin® W rail, Rail

Complementary products



TR
Spur round rack, Stainless steel - module 0,25-1,5



TRMSS
Spur round rack, Stainless steel - module 1-5



G1
Steel spur gear, Steel 20NCD2