
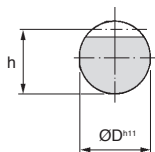


- Pressure angle 20°
- Diameter tolerance h11
- Material:  
drawn stainless steel 304

In stock  
up to module 2

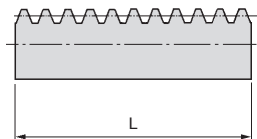

### DISCOUNTS

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Module	h (mm)	ØD (mm)	L (mm)	Stock*	Price each 1 to 2
TRM1-1000/SS	1	9,00	10	999	✓	121,99 €
TRM1.5-1000/SS	1,5	13,50	15	999	✓	176,24 €
TRM2-1000/SS	2	18,00	20	999	✓	171,48 €
TRM2.5-1000/SS	2,5	22,50	25	997	-	On request
TRM3-1000/SS	3	27,00	30	999	-	On request
TRM4-1000/SS	4	36,00	40	1005	-	On request
TRM5-1000/SS	5	45,00	50	1005	-	On request

\*Depending on availability - Dimensions in mm

## Our other products



AT10-32ECO

AT type timing pulley,  
Economy range -  
AT10 aluminium



PRF JL5

Lip seal for panel,  
Door seal - Ø 5mm



BABPass

Hardened stainless  
steel ball pin with  
ring, With grip ring



ACLLPP

Latch for aluminium  
profile, Spring  
operated latch



SHTC

Drylin® Linear table,  
Maintenance free



SCE\_SS

Stainless steel U-  
shaped clamp,  
Stainless seal



MRAeco

Low cost quick link,  
Steel



PMC48\_M8

Anti-vibration  
machine mount, Oval  
base plate



DFG

Flat suction cup,  
nitrile



HTD8M\_20

HTD Heavy duty  
timing pulley, HTD8  
Cast



AT10courroie


AT type timing belt,  
AT10 Steel cored  
polyurethane



EAR

Bearing locknut, Self  
locking locknut - nylon  
lock washer

## Complementary products

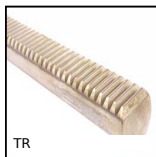

TR

Spur round rack,  
Stainless steel -  
module 0,25-1,5



TRM

Spur round rack, Steel  
- module 1-6



SSG1

Stainless steel spur  
gear, Stainless steel  
304L



SSG1\_304L

Stainless steel spur  
gear, Stainless steel  
304L