
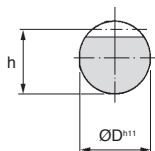
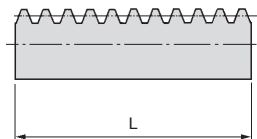


- Pressure angle 20°
- Diameter tolerance h11
- Material:
drawn stainless steel 304

In stock
up to module 2

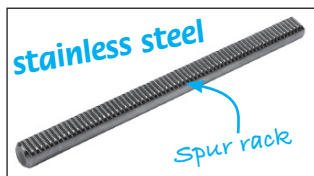

DISCOUNTS

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Module	h (mm)	ØD (mm)	L (mm)	Stock*	Price each 1 to 2
TRM1-1000/SS	1	9,00	10	999	✓	121,99 €
TRM1.5-1000/SS	1,5	13,50	15	999	✓	176,24 €
TRM2-1000/SS	2	18,00	20	999	✓	171,48 €
TRM2.5-1000/SS	2,5	22,50	25	997	-	On request
TRM3-1000/SS	3	27,00	30	999	-	On request
TRM4-1000/SS	4	36,00	40	1005	-	On request
TRM5-1000/SS	5	45,00	50	1005	-	On request

*Depending on availability - Dimensions in mm

Our other products




EHD08-3

Internal epicyclic servo reducers, from 20 to 50 Nm



PRF_RR

 Coupling bar for aluminium profile, Coupling bar



LAT2

2A motorised linear actuator, 2 amperes



GBMz

Cylindrical ballscrew nut, Cylindrical nut - Multiple starts



BPP

Pressed steel flanged bearing for light loads, Sheet steel



BLH60

Right angled gearbox, from 19 to 70 Nm



SLB

Indexing plunger, stainless steel



M0

Worm and wheel set, Bronze



BABPass

Hardened stainless steel ball pin with ring, With grip ring



SH0

Parallel axis helical gear, Steel 20NCD2



GLP

 
Small 6 lobe threaded handle - male, Technopolymer -



CTss

Universal joint, telescopic, Inox, Light duty

Complementary products



TR

Spur round rack, Stainless steel - module 0,25-1,5



TRM

Spur round rack, Steel - module 1-6



SSG1

Stainless steel spur gear, Stainless steel 304L



SSG1_304L

Stainless steel spur gear, Stainless steel 304L