
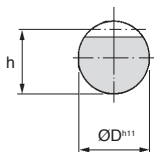
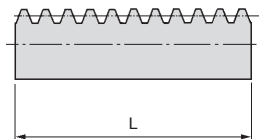


- Pressure angle 20°
- Diameter tolerance h11
- Material:  
drawn stainless steel 304

In stock  
up to module 2

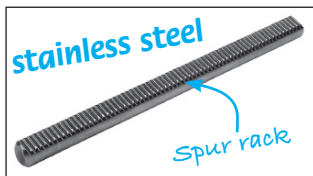

### DISCOUNTS

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Module	h (mm)	ØD (mm)	L (mm)	Stock*	Price each 1 to 2
TRM1-1000/SS	1	9,00	10	999	✓	121,99 €
TRM1.5-1000/SS	1,5	13,50	15	999	✓	176,24 €
TRM2-1000/SS	2	18,00	20	999	✓	171,48 €
TRM2.5-1000/SS	2,5	22,50	25	997	-	On request
TRM3-1000/SS	3	27,00	30	999	-	On request
TRM4-1000/SS	4	36,00	40	1005	-	On request
TRM5-1000/SS	5	45,00	50	1005	-	On request

\*Depending on availability - Dimensions in mm

## Our other products



**METC**  
Bushings, Self-lubricating sintered bronze



**RAGFLOWsupport**  
Handling roller, Roller track support



**WS10**  
Drylin® W modular guidance, Rail



**MHMEP**  
Crank arm with rotating handle, Prebored



**MHSC**  
Flexible coupling, Single disk



**HTD5M\_15**  
HTD-type pulley for RPP-type belt, HTD5 Steel



**BGC**  
Oldham, Clamp



**FDS**  
Flexible drive shaft, Masterflex® Steel, with PVC casing



**CHAK**  
Hinge, Hi-Klik™ - Detent hinge



**PLC\_PLT**  
Magnetic stud, With threaded hole

 


**BLH20**  
Right angled gearbox, from 0.53 to 1.77



**RFV40**  
Worm and wheel gearbox - Stainless steel, up to 47 Nm

## Complementary products



**TR**  
Round spur rack, Stainless steel - module 0,25-1,5



**TRM**  
Round spur rack, Steel - module 1-6



**SSG1**  
Spur gear, Stainless steel 304L



**SSG1\_304L**  
Spur gear, Stainless steel 304L