
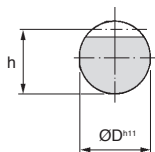
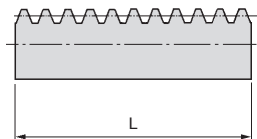


- Pressure angle 20°
- Diameter tolerance h11
- Material:
drawn stainless steel 304

In stock
up to module 2

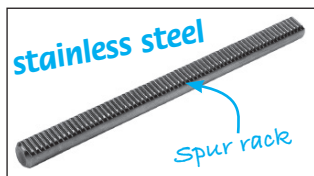


DISCOUNTS

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Module	h (mm)	ØD (mm)	L (mm)	Stock*	Price each 1 to 2
TRM1-1000/SS	1	9,00	10	999	✓	121,99 €
TRM1.5-1000/SS	1,5	13,50	15	999	✓	176,24 €
TRM2-1000/SS	2	18,00	20	999	✓	171,48 €
TRM2.5-1000/SS	2,5	22,50	25	997	-	On request
TRM3-1000/SS	3	27,00	30	999	-	On request
TRM4-1000/SS	4	36,00	40	1005	-	On request
TRM5-1000/SS	5	45,00	50	1005	-	On request


*Depending on availability - Dimensions in mm

 Our other products



PB

 Plastic deep groove ball bearing, Plastic - balls material : staine...




AC

Strike for toggle latch, 15mm



WW10

 Drylin® W slide, slide assembly



KS

Keysteel, Stainless steel - Keystock



TBEBASE10

Economic mini-table with trapezoidal leadscrew, 1kg



BHEX

Hexagonal cap, Black technopolymer



PRF_ART

Articulated bracket for use with aluminium profile, With clamping ha...



DOMI50

Accessories, Plate



T10_30_AL

T type timing pulley, Economy range - T10 aluminium



NCT

Square tube connector, Fixed angle



PRF_ECL

 
Nut for aluminium profile, Steel square nut with tab



DBC

Panamech, Multi-Beam, Aluminium - with clamping jaw

Complementary products



TR

Spur round rack, Stainless steel - module 0,25-1,5



TRM

Spur round rack, Steel - module 1-6



SSG1

Stainless steel spur gear, Stainless steel 304L



SSG1_304L

Stainless steel spur gear, Stainless steel 304L