

# Stem support for caster

For swivel caster with central hole **TSRTC**

## - Threaded stem for swivel castor with central hole

- Material:

Stem: Stainless steel 304

Washer: Stainless steel 304


### Mounting

- Pass the  $\varnothing F$  thread through the center hole of the castor plate and secure with a washer and a M12 lock nut (not supplied)
- If necessary, the length A can be shortened by yourself.
- The protection of the caster can be improved with the stainless steel protective washer **TSR-ROND**


### Accessories

- Swivel castor with central hole **RPC/TC Tome 5** (p. 59), **RBN/TC 5** (p. 67), **RHT/TC 5** (p. 73) and **RURT 5** (p. 70)

Example of assembly with protective washer

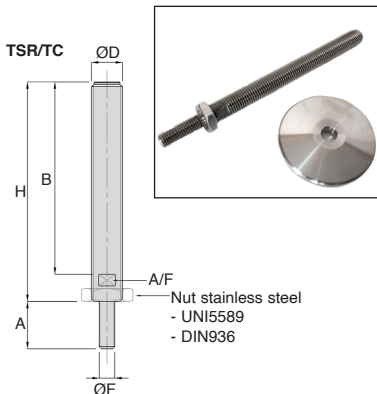

### TSR-ROND

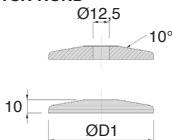

### DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØD	ØF	A	B	H	A/F	ØD1	Stock*	Price each 1 à 9
<b>Threaded stem</b>									
TSR16-150/TC/SS	M16x2	M12x1,75	37	150	171	13	-	-	18,33 €
TSR16-200/TC/SS	M16x2	M12x1,75	37	200	221	13	-	-	21,78 €
TSR20-150/TC/SS	M20x2,5	M12x1,75	37	150	172	17	-	-	24,25 €
TSR20-200/TC/SS	M20x2,5	M12x1,75	37	200	222	17	-	-	29,70 €
TSR24-150/TC/SS	M24x3	M12x1,75	37	150	172	20	-	-	31,68 €
TSR24-200/TC/SS	M24x3	M12x1,75	37	200	222	20	-	-	39,10 €
<b>Protective washer</b>									
TSR-ROND12-60/SS	-	-	-	-	-	-	60	-	14,55 €
TSR-ROND12-80/SS	-	-	-	-	-	-	80	-	19,40 €

\*Depending on availability - Dimensions in mm

## Our other products



CTss

Universal joint, telescopic, Inox, Light duty



DILC

Indexing plunger with cam, with cam



BSM

Spring plunger with internal hexagonal socket, steel body and pin



G0

Steel spur gear, Steel 20NCD2



PGT

Sliding profile, Sliding panel support



PCS50K

Chain sprocket with hardened teeth, 12.7mm (DIN08B-1)



UGAC\_UGET

Actuator guide kit, Coupling for threaded cylinder end



MEFC

Flanged sintered ferrous bush, Self-lubricating FP20 ferrous alloy M...



 
DTR

Chain idler sprocket, Chain idler sprocket - Steel



CM\_CO

Tools Hygienic Usit® and Hygienic Design®, Protective inserts for ...



M0

Worm and wheel set, Machined plastic (delrin)



MSP19

Masterplate® glueable insert Ø19, Cylindrical with tapped insert

## Complementary products



RPCtc

Swivel castor with central hole, Steel - Polyamide



RPCtc

Swivel castor with central hole, Steel - Polyamide - with double brake



RPCtcss

Swivel castor with central hole, Stainless steel - Polyamide



RPCtcss

Swivel castor with central hole, Stainless steel - Polyamide - with ...