

Stem support for caster

For swivel caster with central hole **TSRTC**

- Threaded stem for swivel castor with central hole

- Material:

Stem: Stainless steel 304

Washer: Stainless steel 304



Mounting

- Pass the $\varnothing F$ thread through the center hole of the castor plate and secure with a washer and a M12 lock nut (not supplied)
- If necessary, the length A can be shortened by yourself.
- The protection of the caster can be improved with the stainless steel protective washer **TSR-ROND**

Accessories


- Swivel castor with central hole **RPC/TC Tome 5** (p. 59), **RBN/TC 5** (p. 67), **RHT/TC 5** (p. 73) and **RURT 5** (p. 70)

Example of assembly with protective washer

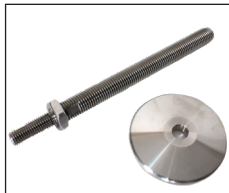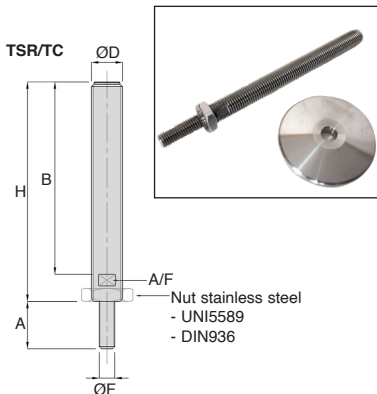

- Nut stainless steel
- UNI5589
- DIN936

TSR-ROND

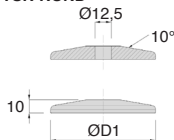

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØD	ØF	A	B	H	A/F	ØD1	Stock*	Price each 1 à 9
Threaded stem									
TSR16-150/TC/SS	M16x2	M12x1,75	37	150	171	13	-	-	18,33 €
TSR16-200/TC/SS	M16x2	M12x1,75	37	200	221	13	-	-	21,78 €
TSR20-150/TC/SS	M20x2,5	M12x1,75	37	150	172	17	-	-	24,25 €
TSR20-200/TC/SS	M20x2,5	M12x1,75	37	200	222	17	-	-	29,70 €
TSR24-150/TC/SS	M24x3	M12x1,75	37	150	172	20	-	-	31,68 €
TSR24-200/TC/SS	M24x3	M12x1,75	37	200	222	20	-	-	39,10 €
Protective washer									
TSR-ROND12-60/SS	-	-	-	-	-	-	60	-	14,55 €
TSR-ROND12-80/SS	-	-	-	-	-	-	80	-	19,40 €

*Depending on availability - Dimensions in mm

Our other products



BH01

Single housed bearing, Bearing fitted with adhesive



HSS

Shoulder screw ISO7379, Hardened Steel class 12.9



UTKpwr

Utilitak® V rail, V rail



ACLCHAR

Hinge for aluminium profile, With elongated holes



PT820

Drive sprocket for slat top chain, Ranges 820 and 815



RAM35

Manual bevel gearbox, Bevel



CQA20

Accessory for adjustment slide-system, 20



ADL_F

Female eye bolt conforms to DIN582, Stainless steel



ERF

Quick fitting threaded cable terminal, Cable terminal with



PR882

Idler sprocket for slat top chain, Range 882



ZG0

Plastic spur gear, Machined plastic (delrin)



CMM

Male rod ends DIN ISO12240-4, Steel / bronze

Complementary products



RPCtc

Swivel castor with central hole, Steel - Polyamide



RPCtc

Swivel castor with central hole, Steel - Polyamide - with double brake



RPCtcss

Swivel castor with central hole, Stainless steel - Polyamide



RPCtcss

Swivel castor with central hole, Stainless steel - Polyamide - with ...