

Stem support for caster

For swivel caster with central hole **TSRTC**

- Threaded stem for swivel castor with central hole

- Material:

Stem: Stainless steel 304

Washer: Stainless steel 304


Mounting

- Pass the $\varnothing F$ thread through the center hole of the castor plate and secure with a washer and a M12 lock nut (not supplied)
- If necessary, the length A can be shortened by yourself.
- The protection of the caster can be improved with the stainless steel protective washer **TSR-ROND**


Accessories

- Swivel castor with central hole **RPC/TC Tome 5** (p. 59), **RBN/TC 5** (p. 67), **RHT/TC 5** (p. 73) and **RURT 5** (p. 70)

Example of assembly with protective washer

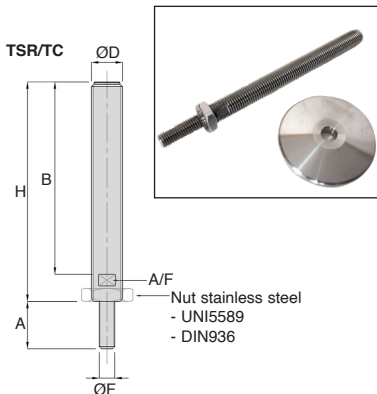

TSR-ROND

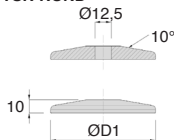

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request


Part number	ØD	ØF	A	B	H	A/F	ØD1	Stock*	Price each 1 à 9
Threaded stem									
TSR16-150/TC/SS	M16x2	M12x1,75	37	150	171	13	-	-	18,33 €
TSR16-200/TC/SS	M16x2	M12x1,75	37	200	221	13	-	-	21,78 €
TSR20-150/TC/SS	M20x2,5	M12x1,75	37	150	172	17	-	-	24,25 €
TSR20-200/TC/SS	M20x2,5	M12x1,75	37	200	222	17	-	-	29,70 €
TSR24-150/TC/SS	M24x3	M12x1,75	37	150	172	20	-	-	31,68 €
TSR24-200/TC/SS	M24x3	M12x1,75	37	200	222	20	-	-	39,10 €
Protective washer									
TSR-ROND12-60/SS	-	-	-	-	-	-	60	-	14,55 €
TSR-ROND12-80/SS	-	-	-	-	-	-	80	-	19,40 €

*Depending on availability - Dimensions in mm

Our other products




PF55
Worm and wheel gear reducer, up to 57 Nm

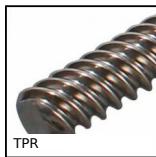

TPR
High helix leadscrew, Leadscrew only - up to 40mm per rotation



BSM
Spring plunger with internal hexagonal socket, steel body, plastic pin

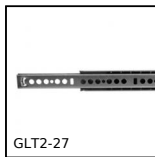

GLT2-27
Telescopic drawer runners for groove mounting, Partial extension



RVM25
Manually operated gearbox, Bevel



H0
Crossed helical gear crossed axis at 90°, Steel 20NCD2



ATZY
Diabolo shaped elasto mount, Steel



INS_SS
Self tapping stainless steel insert, Stainless steel




SH2
Parallel axis helical gear, Steel 20NCD2



SSBRA
Stainless steel bevel gear, 1:1



 RCC_RCX
Spherical tilt washer - DIN6319, concave



PB
Plastic deep groove ball bearing, Plastic - balls material : stainle...

Complementary products



RPCtc
Swivel castor with central hole, Steel - Polyamide



RPCtc
Swivel castor with central hole, Steel - Polyamide - with double brake



RPCtcss
Swivel castor with central hole, Stainless steel - Polyamide



RPCtcss
Swivel castor with central hole, Stainless steel - Polyamide - with ...