

Stainless steel axial thrust bearing

TTBss TBss

For axial loads


- Bearing for axial loads
- With internal groove
- Not suitable for radial load
- Oil lubrication
- Outdoor durability
- Chemical solvent resistant
- Material :
Stainless steel

stainless steel



Info

- **Load ratings are calculated based on steel version. The rates are approximately 20% lower for stainless steel

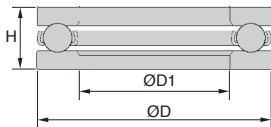


DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-15%	On request

Part Number	ØD1	ØD	H	Load capacity**		Max speed (rpm)		Weight (g)	Stock*	Price each 1 to 3
				Dynamic C	Static Co	Lubrication Grease	Oil			
TTB3/SS	3	8	3,5	-	-	-	15000	↻		
TTB4/SS	4	10	4	-	-	-	15000	↻		
TTB5/SS	5	12	4	-	-	-	13000	↻		
TTB6/SS	6	14	5	-	-	-	10000	↻		
TTB7/SS	7	17	6	-	-	-	10000	↻		
TTB8/SS	8	19	7	-	-	-	8000	↻		

*Depending on availability - Dimensions in mm

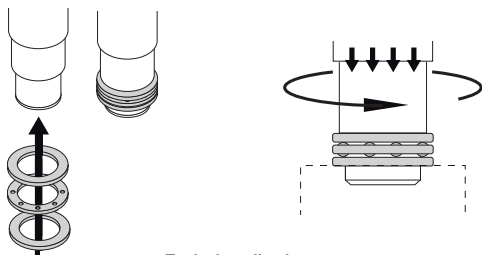

Typical application

DISCOUNTS

Qty	1+	4+	10+
Disc.	List	-15%	On request

Part Number	ØD1	ØD	H	Load capacity**		Max speed (rpm)		Weight (g)	Price each 1 to 3
				Dynamic C	Static Co	Lubrication Grease	Oil		
TB51100/SS	10	24	9	-	-	7500	9500	20	
TB51200/SS	10	26	11	-	-	6000	8000	29	
TB51101/SS	12	26	9	-	-	7000	9500	22	
TB51201/SS	12	28	11	-	-	6000	8000	32	
TB51102/SS	15	28	9	-	-	6300	8500	24	
TB51202/SS	15	32	12	-	-	5000	6700	43	
TB51103/SS	17	30	9	-	-	6300	8500	28	
TB51203/SS	17	35	12	-	-	5000	6700	50	
TB51104/SS	20	35	10	-	-	5600	7500	40	
TB51204/SS	20	40	14	-	-	4300	5600	82	
TB51105/SS	25	42	11	-	-	4800	6300	59	
TB51305/SS	25	47	15	-	-	3800	5000	120	
TB51106/SS	30	47	11	-	-	4500	6000	68	
TB51306/SS	30	52	16	-	-	3600	4500	150	
TB51107/SS	35	52	12	-	-	4300	5600	90	
TB51307/SS	35	62	18	-	-	3000	4000	220	
TB51108/SS	40	60	13	-	-	3800	5000	120	
TB51308/SS	40	68	19	-	-	2900	3800	270	
TB51109/SS	45	65	14	-	-	3400	4500	150	
TB51309/SS	45	73	20	-	-	2500	3500	320	
TB51110/SS	50	70	14	-	-	3300	4500	160	
TB51310/SS	50	78	22	-	-	2400	3400	390	
TB51111/SS	55	78	16	-	-	2700	3800	240	
TB51311/SS	55	90	25	-	-	1900	2800	610	
TB51112/SS	60	85	17	-	-	2600	3700	290	
TB51311/SS	55	90	25	-	-	1900	2800	610	
TB51112/SS	60	85	17	-	-	2600	3700	290	

*Depending on availability - Dimensions in mm

Our other products



EKG5

Backlash free coupling Gerwah®, from 0.5 to 35Nm



CM

Tools Hygienic Usit® and Hygienic Design®, Combination spanner



HSE-HSB

Hexagonal spacer, Brass




SRG

Adjustable latch clamp with strike plate, Stroke from 96mm to 121,7mm



RHTplss

High Temperature Castor, up to 200kg

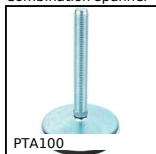

PTA100

Articulated levelling foot, pressed base Ø100, 15000N



BLHB60

Right angled gearbox, bored shafts, up to 70 Nm



RFK38B

Hypoid gearbox - Stainless steel, up to 200 Nm



CHAPAMss

Weld-on hinge with flat end, Stainless steel or Aluminium



BPFL

Sheet steel flanged bearing for light loads, Sheet steel



SERB

Universal latch key, Universal latch key



HLUT

Spoked handwheel with handle, Aluminium

Complementary products



TBbutee

Axial thrust bearing, Steel balls



TB8

Cylindrical roller thrust bearing, Steel