


- **Structural tube**
- Materials: Stainless steel or anodised aluminium
- Square tube 25 x 25mm

Accessories

- Connectors **NCT**
- Caps **BTC**
- Slide profiles **PGT**
- Support profiles **PSP**

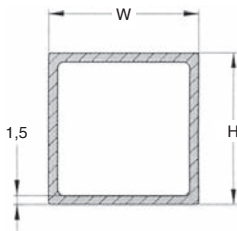

DISCOUNTS

Qty	1+	10+	21+
Disc.	List	-5%	On request

Part number	Material	H	W	Length (mm)	Weight (kg/m)	Stock*	Price each 1 to 9
TUBE25-25/SS	Stainless steel	25	25	3000	3,21	✓	75,45 €
TUBE25-25/AL	Aluminium	25	25	3000	1,09	✓	51,88 €

*Depending on availability - Dimensions in mm

Our other products



SCA_SS

Stainless steel flat cable clamp, Stainless steel



PRES5HR

Manual workbench press, Force up to 500kg



PRFRTR

Cross connector for aluminium profile, Cross connector



GP

Spring loaded toggle latch, With padlock-holder



WJUM10

Drylin® W bearing block, Slide



G-ECO

Eco range Spur gear, Steel C45



RBGtc

Swivel castor with central hole, Steel - grey rubber - with double b...



CHB

Feet, For CHB gearbox



MHX

Hexagonal threaded sleeve, Hexagonal - steel



 
DTR

Chain idler sprocket, Chain idler sprocket - Steel



BPHT

Ball transfer unit bolt fitting, Heavy



SBS_M

Single chain supplied by the metre, Stainless steel

Complementary products



BTC

End cap for square tube, Standard



NCT_AT

Variable angle connector, Variable angle



NCT

Square tube connector, Fixed angle



NCT

Square tube connector, Fixed angle