

Rubber cover for universal joints




U8R

For use with U816 - U832


- Increases length of life of universal joints
- Material:
 - Synthetic rubber
- PVC Shore A 1,18g/cm²
- Electrical resistance $8 \times 10^9 \Omega \text{cm}$
- Working temperature:
 - Continuous -27°C to +70°C
 - Occasional -32°C to +120°C

Advantages

- Oil-resistant
- Good elasticity

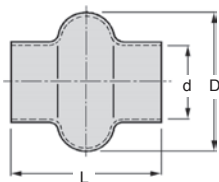

For single joint

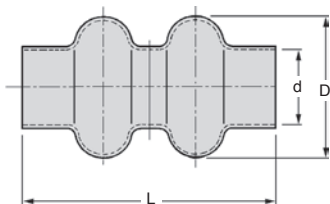

For double joint

DISCOUNTS

Qty	1+	5+	10+	25+	50+
Disc.	List	-6%	-12%	-18%	On request

Part number	For joint	d	L	D	Stock*	Price each 1 to 4
For single joint						
U8R-02	U816A	16	32	35	-	11,64 €
U8R-04	U820A	20	40	36	✓	16,99 €
U8R-1	U825A	24	45	44	✓	12,73 €
U8R-3	U832A	32	55	62	✓	15,48 €
For double joint						
U8R-19	U816C	16	55	35	-	20,52 €
U8R-20	U820C	20	65	36	✓	22,46 €
U8R-21	U825C	24	70	44	✓	26,01 €
U8R-23	U832C	32	90	62	-	31,10 €

*Depending on availability - Dimensions in mm

Our other products



QTC
Clip on Quarter turn
latch, Slotted head



PF20
Worm and wheel
gearbox, up to 5 Nm



HTD5M_09
HTD-type pulley for
RPP-type belt, HTD5
Steel



DH
Dowel pin, Solid DIN
6325




PM4
Worm, Hardened steel



STL
Guidance brush, Rail



CAP882
Flexible plate chain,
Large range 882

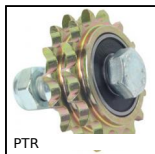


PTR
Idler chain sprocket,
For standard
applications



PV2R
Adjustable suction-cup
support,
Increased grip



 PF55
Worm and wheel
gearbox, up to 57 Nm



GPLac
Brush, steel



SVT15
Screwjack, with
translating screw

Complementary products



UC
Universal joint - steel,
Double



U8R
Bellows cover, Low
cost