
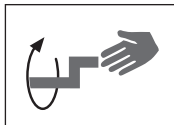


- **Conforms to DIN 7551-E (size 13)**
or DIN 808-E
(sizes 16 to 40)
- Light duty applications
- Manual operation or infrequent use
- Misalignment angle 70°
- Material:
Steel 95MnPb28

Uses

- Stress valve
- Valve drive
- Blinds

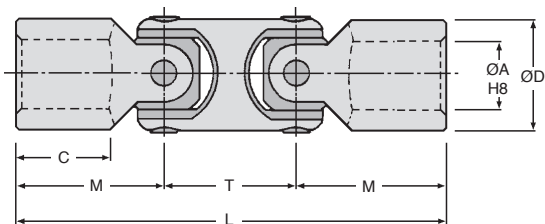

For manual
application

DISCOUNTS

Qty	1+	5+	10+	25+	50+
Disc.	List	-6%	-12%	-18%	On request

Part number	ØD	Bore ØA	C	M	T	L	Max speed (rpm)	Backlash Nm (min)	Stock*	Price each 1 to 4
U813C	13	8	11	21	18	60	200	- -	✓	26,40 €
U816C	16	10	15	26	22	74	200	0,2 1°30'	✓	25,32 €
U820C	20	12	18	31	26	88	200	0,4 1°20'	✓	30,73 €
U825C	25	16	22	37	30	104	200	1,0 1°04'	✓	62,03 €
U832C	32	20	25	43	37	123	200	1,7 0°56'	✓	63,36 €

*Depending on availability - Dimensions in mm

Our other products



CHA_GC_955

Stainless steel garnet hinge, To be welded




AC156-157

Catch plate for toggle latch, 25.5mm



BMM

Knob for clamping, Knurled

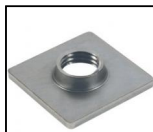

BTCW

Tube end cap, To be welded



SKM

Trapezoidal nut, Steel - 1 thread



RJA10_03

Linear sealing strip, Clipping



MHXred

Reducing sleeve, Hexagonal - stainless steel



RPCtc

Wheel pivoting with central hole, Steel - Polyamide - with double brake



RJA11_27

Linear sealing strip, Not clipping



PRF_ECL

Fixing, Steel square nut with tab



FRTC_FRNC

Rotary dampener, 2 and 3Ncm



QTR

Tapered roller bearing, Steel

Complementary products



U8R

Bellows cover, Low cost



UA

Universal joint - steel, Single