



# Stainless steel/Polymer flanged bearing

## 4 mounting points

## UCFPBT

- Self aligning bearing with 4 mounting points
- Interchangeable with cast iron units
- Grease applicator supplied
- Working temperature: -35°C to +102°C
- Materials:
  - Bearing: Stainless steel AISI 440C
  - Housing: PBT polymer
  - Grease: suitable for food industry



### Colour

- UCF/PBT/G: green
- UCF/PBT/W: white

### Accessory

- Protective cover

**For the food industry**

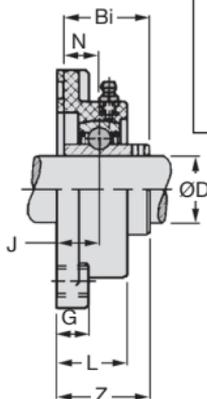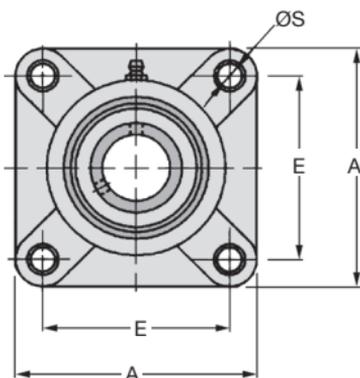

### DISCOUNTS

Qty	1+	10+	26+	51+
Disc.	List	-10%	-20%	On request

Part number	ØD	A	E	G	L	ØS	Z	J	Bi	N	Stock*	Price each
UCF201/PBT/G	12	86	63,5	13,4	27,8	11	36,3	18,0	31,0	12,7	✓	92,35 €
UCF202/PBT/G	15	86	63,5	13,4	27,8	11	36,3	18,0	31,0	12,7	✓	87,89 €
UCF203/PBT/G	17	86	63,5	13,4	27,8	11	36,3	18,0	31,0	12,7	-	82,15 €
UCF204/PBT/W	20	86	63,5	13,4	27,8	11	36,3	18,0	31,0	12,7	✓	21,38 €
UCF205/PBT/W	25	95	70,0	14,0	28,0	11	36,7	17,0	34,0	14,3	✓	27,95 €
UCF206/PBT/W	30	107	83,0	14,3	31,5	11	41,4	19,2	38,1	15,9	✓	40,41 €
UCF207/PBT/W	35	118	92,0	15,5	34,8	13	46,9	21,5	42,9	17,5	-	50,30 €
UCF208/PBT/W	40	130	102,0	17,0	37,5	14	53,2	23,0	49,2	19,0	✓	61,54 €

\*Depending on availability - Dimensions in mm

## Our other products



M1

Worm , Hardened steel



PF20

Worm and wheel gear reducer, up to 5 Nm



HLA28

Right angle spiro bevel gearbox, Up to 182Nm



LOQ

Manual lock, Manual latch



PF40

Worm and wheel gear reducer, up to 18 Nm



SH1

Parallel axis helical gear, Steel 20NCD2



BRI

Panel holder, Panel holder



ACM\_TRI

Manual bonnet fastener, Black rubber fastener



CMM

Male rod ends DIN ISO12240-4, Steel /



ZDB

Machined plastic bevel gear , 2:1



E30

Right angle helical reducers, from 1.50 to



ZY

Conical elasto buffer, Stainless steel

## Complementary products



UCP\_PBT

Stainless/Polymer pillow block bearing, Polymer and stainless steel



UCFL\_PBT

Stainless steel/Polymer flanged bearing, Polymer and stainless steel



BPFss

Pressed stainless steel flange bearing, Stainless steel



UCF\_PBT

Stainless steel/Polymer flanged bearing, Polymer and stainless steel