

UCFss


4 mounting points

- Self aligning bearing with 4 mounting points
- Interchangeable with cast iron units
- Working temperature range: until +140°C
- Material:

Bearing: stainless steel

Housing: stainless steel

For hostile environments

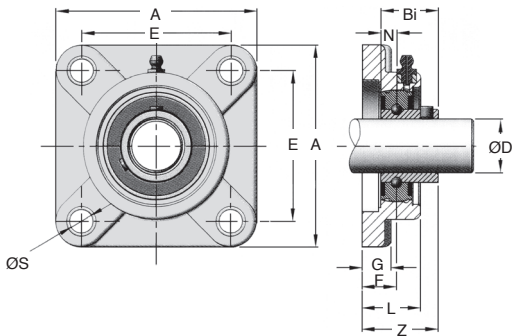

DISCOUNTS

Qty	1+	10+	26+
Disc.	List	-10%	On request

Part number	ØD	A	E	G	L	ØS	Z	F	Bi	N	Weight (kg)	Stock*	Prix Uni.
												1 à 9	
UCF204/SS	20	86	64	11	25	12	33,3	15	31,0	12,7	0,60	✓	50,71 €
UCF205/SS	25	95	70	13	27	12	35,8	16	34,1	14,3	0,86	✓	48,47 €
UCF206/SS	30	108	83	13	31	12	40,1	18	38,1	15,9	1,10	✓	78,00 €
UCF207/SS	35	117	92	15	34	14	44,4	19	42,9	17,5	1,60	-	96,61 €
UCF208/SS	40	130	102	15	36	16	51,2	21	49,2	19,0	1,90	✓	111,95 €

*Depending on availability - Dimensions in mm

Our other products



HG5-ECO

Eco range Spur gear,
Steel C45



BMM

Knurled knob - male,
Knurled



PSG255

Spur gear - precision
range, Stainless steel
316



 
T5P_T10P

Connecting plate for T
type timing belts, T10



APB_BOU

Protective cap, Safety
cap



GPLny

Brush, nylon
cap



LRX

Linear roller slide,
Chariot - from 9410 N
to 101000 N



PRF_ECL

Nut for aluminium
profile, Steel square
nut with tab



RVM14

Manual worm and
wheel gearbox,
Worm/wheel



SSDB

Stainless steel bevel
gear, 2:1



EHD08-3

Internal epicyclic
servo reducers, from
20 to 50 Nm



ADL_M

Male eye bolt
conforms to DIN580,
Steel

Complementary products



UCP_SS

Stainless steel pillow
block bearing,
Stainless steel



UCFL_SS

Stainless steel flanged
bearing, Stainless
steel



BPFss

Pressed stainless
steel flange bearing,
Stainless steel