

UCFss


4 mounting points

- Self aligning bearing with 4 mounting points
- Interchangeable with cast iron units
- Working temperature range: until +140°C
- Material:

Bearing: stainless steel

Housing: stainless steel

For hostile environments

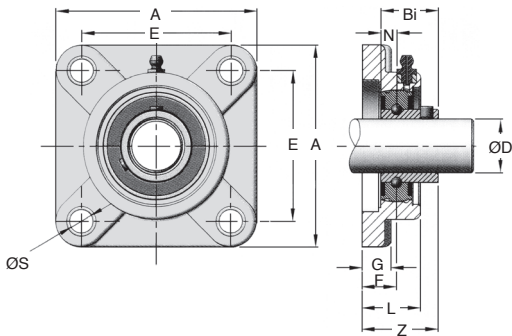

DISCOUNTS

Qty	1+	10+	26+
Disc.	List	-10%	On request

Part number	ØD	A	E	G	L	ØS	Z	F	Bi	N	Weight (kg)	Stock*	Prix Uni.
												1 à 9	
UCF204/SS	20	86	64	11	25	12	33,3	15	31,0	12,7	0,60	✓	50,71 €
UCF205/SS	25	95	70	13	27	12	35,8	16	34,1	14,3	0,86	✓	48,47 €
UCF206/SS	30	108	83	13	31	12	40,1	18	38,1	15,9	1,10	✓	78,00 €
UCF207/SS	35	117	92	15	34	14	44,4	19	42,9	17,5	1,60	-	96,61 €
UCF208/SS	40	130	102	15	36	16	51,2	21	49,2	19,0	1,90	✓	111,95 €

*Depending on availability - Dimensions in mm

Our other products



ABL100005

Antistatic brush,
Standard



RDERSS

Stainless steel manual
rigging screw,
Stainless steel -
manual



SH0

Parallel axis helical
gear, Machined plastic
(delrin)



NAST

Cam follower without
axial guide, With
interior ring



CHV

Mechanical speed
variator, from 0,18 to
1,5kW



AKD

Bellows coupling
Gerwah®, from 22 to
600Nm




NDS20

Double cross clamp,
Crossed



PRF_PL_4590

 Joining plate for
aluminium profile,
joint plate - 45x90
mm



PO

Pull handle - Multi-
sector, Smooth hole



ZG2

Plastic spur gear,
Machined plastic
(delrin)



PRFSRAD

Dual lock for
aluminium profile,
Quick fitting, self



HTD8M_20

HTD Heavy duty
timing pulley, HTD8
Steel

Complementary products



 
UCP_SS

Stainless steel pillow
block bearing,
Stainless steel



UCFL_SS

Stainless steel flanged
bearing, Stainless
steel



SBF

Sealed flange bearing
unit for Food Industry,
cover



SBF

Sealed flange bearing
unit for Food Industry,
cover