



Stainless steel flanged bearing


2 mounting points

UCFLss

- Self aligning bearing with 2 mounting points
- Interchangeable with cast iron bearings
- Working temperature range: until +140°C
- Material:

Bearing: stainless steel
Housing: stainless steel

For hostile environments

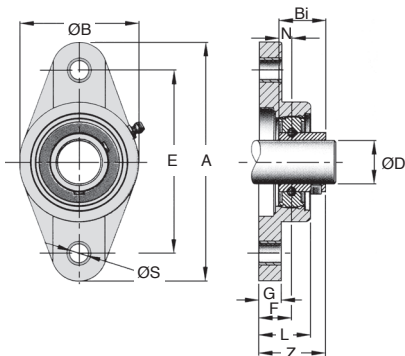

DISCOUNTS

Qty	1+	10+	26+
Disc.	List	-10%	On request

Part number	ØD	A	E	G	L	ØS	Z	F	ØB	Bi	N	Weight		Price each
												(kg)	Stock*	
UCFL204/SS	20	113	90	10	25,5	12	33,3	15	60	31,0	12,7	0,48	✓	36,72 €
UCFL205/SS	25	130	99	10	27,0	16	35,8	16	68	34,1	14,3	0,63	✓	44,88 €
UCFL206/SS	30	148	117	10	31,0	16	40,2	18	80	38,1	15,9	0,89	✓	64,30 €
UCFL207/SS	35	161	130	11	34,0	16	44,4	19	90	42,9	17,5	1,21	-	86,33 €
UCFL208/SS	40	175	144	11	36,0	16	51,2	21	100	49,2	19,0	1,60	-	109,87 €

*Depending on availability - Dimensions in mm

Our other products



PM4

Worm and wheel set,
Non hardened steel



G-ECO

Eco range Spur gear,
Steel C45



PTA80

Articulated levelling
foot, pressed base
Ø80, Ø 80



PLM-16A

Magnetic stud with
threaded hole, With
threaded hole



CAP815

Slim slat top chain
stainless steel,
Narrow range 815



RJUM05

Drylin R® linear
bearing housing,
Closed - Slim



BSPT

Single rod clip, Round



BTE

Universal tension arm,
For normal
applications



SPIT

Floor mounting
levelling plate, With



DOMI30

Accessories, Plate



IBjss

Ball and socket joint,
Stainless steel



TFR

Rigid manual
tensioner, Fixed

Complementary products



UCP_SS

Stainless steel pillow
block bearing,
Stainless steel



UCF_SS

Stainless steel flanged
bearing, Stainless
steel



SBF

Sealed flange bearing
unit for Food Industry,
cover



SBF

Sealed flange bearing
unit for Food Industry,
cover