



Stainless steel flanged bearing


2 mounting points

UCFLss

- Self aligning bearing with 2 mounting points
- Interchangeable with cast iron bearings
- Working temperature range: until +140°C
- Material:

Bearing: stainless steel
Housing: stainless steel

For hostile environments

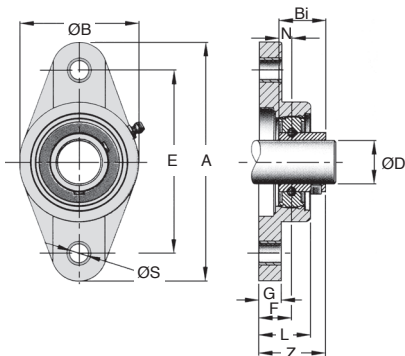

DISCOUNTS

Qty	1+	10+	26+
Disc.	List	-10%	On request

Part number	ØD	A	E	G	L	ØS	Z	F	ØB	Bi	N	Weight		Price each
												(kg)	Stock*	
UCFL204/SS	20	113	90	10	25,5	12	33,3	15	60	31,0	12,7	0,48	✓	36,72 €
UCFL205/SS	25	130	99	10	27,0	16	35,8	16	68	34,1	14,3	0,63	✓	44,88 €
UCFL206/SS	30	148	117	10	31,0	16	40,2	18	80	38,1	15,9	0,89	✓	64,30 €
UCFL207/SS	35	161	130	11	34,0	16	44,4	19	90	42,9	17,5	1,21	-	86,33 €
UCFL208/SS	40	175	144	11	36,0	16	51,2	21	100	49,2	19,0	1,60	-	109,87 €

*Depending on availability - Dimensions in mm

Our other products



SCE
U-shaped cable clamp, Steel



E50
Right angle helical reducers, from 3 to 41 Nm



 
TSRTC
Stem support for caster, For swivel caster with central hole



G-ECO
Eco range Spur gear, Steel C45



SEV
Vertical stirrup toggle clamp, Vertical Latch Clamp - steel




VKM
Square steel nut, Steel - 1 thread



RTE
Rotex®, jaw coupling, cast iron



 CHAK
Hi-Klik™ indent hinge, Hi-Klik™ - Detent hinge



PRF4545r90
Standard aluminium profile, 45 x 45 mm - R90°



SEV
Vertical stirrup toggle clamp, Vertical Latch Clamp - stainless steel



CHAEss
Decorative hinge, Stainless steel



NT63
Spur gear coaxial gearbox, from 8 to 20 Nm - Inline

Complementary products



UCP_SS
Stainless steel pillow block bearing, Stainless steel



UCF_SS
Stainless steel flanged bearing, Stainless steel



SBF
Sealed flange bearing unit for Food Industry, cover



SBF
Sealed flange bearing unit for Food Industry, cover