



Stainless steel flanged bearing

2 mounting points


UCFLss

- Self aligning bearing with 2 mounting points
- Interchangeable with cast iron bearings
- Working temperature range: until +140°C
- Material:

Bearing: stainless steel
Housing: stainless steel

For hostile environments

stainless steel

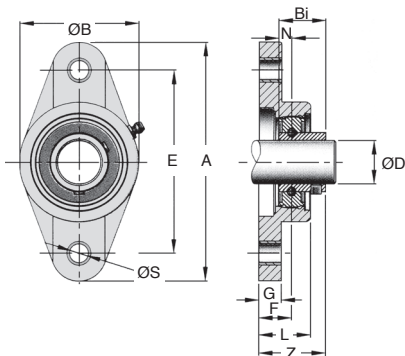

DISCOUNTS

Qty	1+	10+	26+
Disc.	List	-10%	On request

Part number	ØD	A	E	G	L	ØS	Z	F	ØB	Bi	N	Weight		Price each
												(kg)	Stock*	
UCFL204/SS	20	113	90	10	25,5	12	33,3	15	60	31,0	12,7	0,48	✓	36,72 €
UCFL205/SS	25	130	99	10	27,0	16	35,8	16	68	34,1	14,3	0,63	✓	44,88 €
UCFL206/SS	30	148	117	10	31,0	16	40,2	18	80	38,1	15,9	0,89	✓	64,30 €
UCFL207/SS	35	161	130	11	34,0	16	44,4	19	90	42,9	17,5	1,21	-	86,33 €
UCFL208/SS	40	175	144	11	36,0	16	51,2	21	100	49,2	19,0	1,60	-	109,87 €

*Depending on availability - Dimensions in mm

Our other products



GLT3-46

Telescopic drawer,



 
GLS

Stainless steel gas spring, Stainless steel



BPM

Slotted spring plunger with ball tip, Stainless steel 303



BLHM60

Right angled gearbox, double output shafts, up to 70 Nm



AC144

Strike for toggle latch, 22mm



GLT2-17

Telescopic drawer runners for groove mounting, Partial extension



OP2

Mechanical digital position indicator, 3 numbers



M

Bellows cover, Accessory:




BAG-MI

Split shaft collar with clamp lever, Steel



BABreceptacle

Ball pin socket, Socket

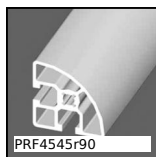

PRF4545r90

Standard aluminium profile, 45 x 45 mm -



PGMT

Pull handle, Stainless steel

Complementary products



UCP_SS

Stainless steel pillow block bearing, Stainless steel



UCF_SS

Stainless steel flanged bearing, Stainless steel



SBF

Sealed flange bearing unit for Food Industry, cover



SBF

Sealed flange bearing unit for Food Industry, cover