

Stainless steel/Polymer flanged bearing

UCFLPBT

2 mounting points

- Self aligning bearing with 2 mounting points
- Interchangeable with cast iron units
- Grease applicator supplied
- Working temperature: -35°C to +102°C
- Materials:
 - Bearing: Stainless steel AISI 440C
 - Housing: PBT polymer
 - Grease: suitable for food industry




Colour

- UCFL/PBT/G: green
- UCFL/PBT/W: white

Accessory

- Protective cover

For the food industry

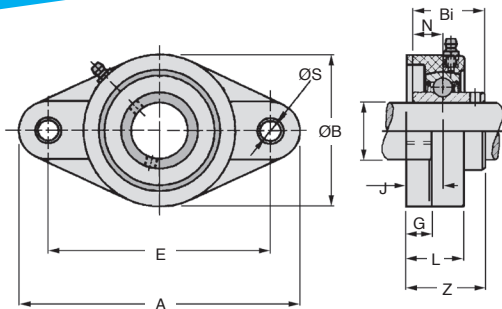

DISCOUNTS

| Qty | 1+ | 10+ | 26+ | 51+ |
|-------|------|------|------|------------|
| Disc. | List | -10% | -20% | On request |

| Part number | ØD | A | E | ØB | G | L | ØS | Z | J | Bi | N | Stock* | Price each 1 to 9 |
|---------------|----|-----|-----|-------|------|------|----|------|------|------|------|--------|----------------------|
| UCFL201/PBT/G | 12 | 113 | 90 | 65,0 | 11,4 | 26,5 | 11 | 33,7 | 15,4 | 31,0 | 12,7 | ✓ | 90,67 € |
| UCFL202/PBT/G | 15 | 113 | 90 | 65,0 | 11,4 | 26,5 | 11 | 33,7 | 15,4 | 31,0 | 12,7 | ✓ | 86,30 € |
| UCFL203/PBT/G | 17 | 113 | 90 | 65,0 | 11,4 | 26,5 | 11 | 33,7 | 15,4 | 31,0 | 12,7 | - | 82,15 € |
| UCFL204/PBT/W | 20 | 113 | 90 | 64,0 | 11,4 | 26,5 | 11 | 33,7 | 15,4 | 31,0 | 12,7 | ✓ | 22,53 € |
| UCFL205/PBT/W | 25 | 130 | 99 | 69,0 | 13,5 | 29,1 | 11 | 36,7 | 17,0 | 34,0 | 14,3 | ✓ | 26,17 € |
| UCFL206/PBT/W | 30 | 148 | 117 | 80,0 | 13,3 | 30,5 | 11 | 41,2 | 19,0 | 38,1 | 15,9 | - | 34,91 € |
| UCFL207/PBT/W | 35 | 164 | 130 | 90,0 | 16,1 | 32,8 | 13 | 43,4 | 18,0 | 42,9 | 17,5 | - | 49,62 € |
| UCFL208/PBT/W | 40 | 176 | 144 | 100,0 | 20,0 | 37,5 | 14 | 51,7 | 21,5 | 49,2 | 19,0 | - | 58,94 € |

*Depending on availability - Dimensions in mm

Our other products



DIL
Lever operated locking bolt, lever clamp



PTKFss
Fixable foot for the food industry, Stainless steel - 3-A standard



STU
Stroke rotary bushing, Steel



BTE
Universal tension arm, For standard applications



KB_UU
Closed linear precision bearing, Precision - steel



MEP
Revolving handle for handwheel, Fixed




CHM40-MOT
Asynchronous AC motorgearboxes 0.18 to 0.55kW, 0.18 to 0.55kW



CHA138
Screwed hinge with threaded insert, 138 degrees



 DB
Steel bevel gear, 2:1



MF
Shock Absorber -universal flange, Universal fixing



GLT3E-58
Telescopic drawer,




E60B
Right angle helical reducers, from 4.50 to 24 Nm

Complementary products



UCP_PBT
Stainless/Polymer pillow block bearing, Polymer and stainless steel

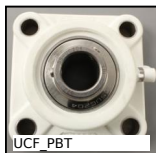

UCF_PBT
Stainless steel/Polymer flanged bearing, Polymer and stainless steel



BPFLss
Pressed stainless steel flange bearing, Stainless steel



UCFL_PBT
Stainless steel/Polymer flanged bearing, Polymer and stainless steel