



# Stainless steel pillow block bearing





2 mounting points

UCPss

- Self aligning bearing with 2 mounting points
- Interchangeable with cast iron units
- Working temperature range: until +140°C
- Materials:  
Bearing: stainless steel  
Housing: stainless steel

stainless steel

For hostile environments

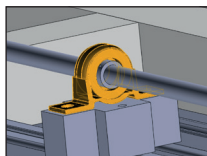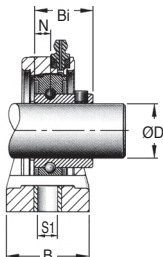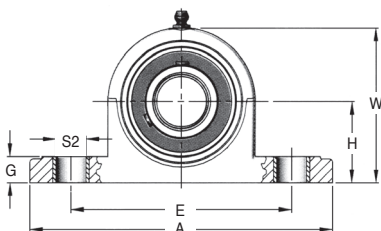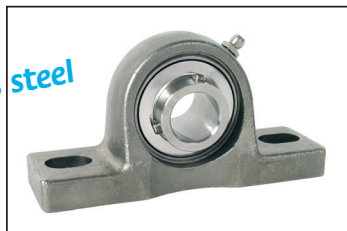

Typical application

## DISCOUNTS

Qty	1+	10+	26+
Disc.	List -10%	On request	On request

Part number	ØD	H	A	E	B	S1	S2	G	W	Bi	N	Weight (kg)	Stock*	Price each 1 to 9
UCP204/SS	20	33,3	127	95,0	38	13,0	19,0	13,0	65,0	31,0	12,7	0,70	✓	53,12 €
UCP205/SS	25	36,5	140	105,0	38	13,0	19,0	15,0	71,0	34,1	14,3	0,85	✓	58,67 €
UCP206/SS	30	42,9	165	121,0	48	17,0	20,0	17,0	84,0	38,1	15,9	1,20	✓	82,74 €
UCP207/SS	35	47,6	167	127,0	48	17,0	19,0	19,0	93,0	42,9	17,5	1,70	✓	116,28 €
UCP208/SS	40	49,2	184	137,0	54	17,0	20,0	20,0	98,0	49,2	19,0	2,10	✓	134,80 €

\*Depending on availability - Dimensions in mm

## Our other products



AT5P\_AT10P  
Connecting plate for  
AT type timing belts,  
AT5



T5P\_T10P  
Connecting plate for T  
type timing belts, T10



AC  
Strike for toggle latch,  
15mm



AT5-16ECO  
AT type timing pulley,  
Economy range - AT5  
aluminium



ES  
Bipod support base,  
Plastic



CHA35  
Hinge for aluminium  
profile, Hinge



BOX-CSss  
Hose clamp, Box set  
of stainless steel hose  
clamps



TFR  
Rigid manual  
tensioner, Fixed



DOG111  
Motor-gearbox 12V  
and 24V DC, from 1.5  
to 6 Nm



SSDB  
Stainless steel bevel  
gear, 2:1



PSG25  
Spur gear - precision  
range, Pre-hardened  
Steel 35NCD6



PRF\_RR  
Coupling bar for  
aluminium profile,  
Coupling bar

## Complementary products



UCF\_SS  
Stainless steel flanged  
bearing, Stainless  
steel



UCFL\_SS  
Stainless steel flanged  
bearing, Stainless  
steel



BPPss  
Pressed stainless  
steel pillow block,  
Stainless steel