



Stainless steel pillow block bearing





2 mounting points

UCPss

- Self aligning bearing with 2 mounting points
- Interchangeable with cast iron units
- Working temperature range: until +140°C
- Materials:
 Bearing: stainless steel
 Housing: stainless steel

stainless steel

For hostile environments

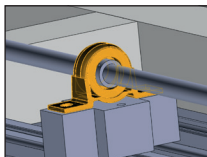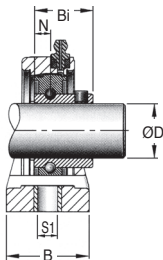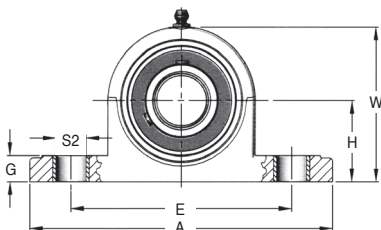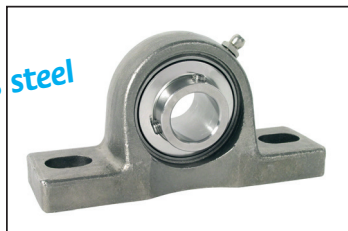

Typical application

DISCOUNTS

Qty	1+	10+	26+
Disc.	List -10%	On request	

Part number	ØD	H	A	E	B	S1	S2	G	W	Bi	N	Weight (kg)	Price each	
													Stock*	1 to 9
UCP204/SS	20	33,3	127	95,0	38	13,0	19,0	13,0	65,0	31,0	12,7	0,70	✓	53,12 €
UCP205/SS	25	36,5	140	105,0	38	13,0	19,0	15,0	71,0	34,1	14,3	0,85	✓	58,67 €
UCP206/SS	30	42,9	165	121,0	48	17,0	20,0	17,0	84,0	38,1	15,9	1,20	✓	82,74 €
UCP207/SS	35	47,6	167	127,0	48	17,0	19,0	19,0	93,0	42,9	17,5	1,70	✓	116,28 €
UCP208/SS	40	49,2	184	137,0	54	17,0	20,0	20,0	98,0	49,2	19,0	2,10	✓	134,80 €

*Depending on availability - Dimensions in mm

Our other products



ERF

Quick fitting threaded cable terminal, Cable terminal with threaded ...



WSS

Symmetrical S shaped hook, Steel




BLHM50

Right angled gearbox, double output shafts, up to 30 Nm



H3

 Crossed helical gear crossed axis at 90°, Steel 20NCD2



SLVhlok

Vertical toggle clamp, Vertical toggle clamp / horizontal foot




ZBconique

Machined plastic bevel gear, 1:1



PDD

Actuating plunger, Non-rotating detector shaft

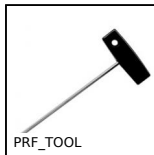

PRF_TOOL

Assembly key for aluminium profile, Assembly key



LRR

Spring loaded latch, Spring loaded latch



PSPD18

Flexible tube handle, Black PVC



PSG3

Spur gear - precision range, Pre-hardened Steel 35NCD6



CLA

Clamping lever Hygienic Usit® - female, Stainless steel

Complementary products



UCF_SS

Stainless steel flanged bearing, Stainless steel



UCFL_SS

Stainless steel flanged bearing, Stainless steel



BPPss

Pressed stainless steel pillow block, Stainless steel