






- Self aligning bearing with 2 mounting points

- Interchangeable with cast iron units
- Working temperature range: until +140°C
- Materials:
  - Bearing: stainless steel
  - Housing: stainless steel

stainless steel

For hostile environments

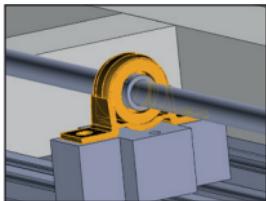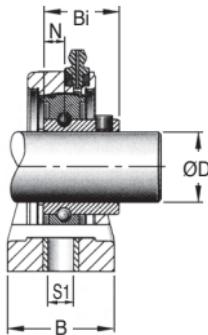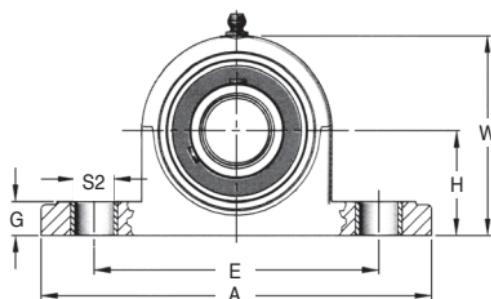

Typical application

## DISCOUNTS

Qty	1+	10+	26+
Disc.	List -10%		On request

Part number	ØD	H	A	E	B	S1	S2	G	W	Bi	N	Weight (kg)	Stock*	Price each 1 to 9
UCP204/SS	20	33,3	127	95,0	38	13,0	19,0	13,0	65,0	31,0	12,7	0,70	✓	53,12 €
UCP205/SS	25	36,5	140	105,0	38	13,0	19,0	15,0	71,0	34,1	14,3	0,85	✓	58,67 €
UCP206/SS	30	42,9	165	121,0	48	17,0	20,0	17,0	84,0	38,1	15,9	1,20	✓	82,74 €
UCP207/SS	35	47,6	167	127,0	48	17,0	19,0	19,0	93,0	42,9	17,5	1,70	✓	116,28 €
UCP208/SS	40	49,2	184	137,0	54	17,0	20,0	20,0	98,0	49,2	19,0	2,10	✓	134,80 €

\*Depending on availability - Dimensions in mm

## Our other products



PRS30  
Stainless steel articulated foot Ø30, Ø 30



CHTRP  
Single and dual output gearboxes, Up to 9,1 Nm



AC  
Strike for toggle latch, 15mm



ACLBTS  
Closing system for aluminium profile, Spacer for spherical ended stop



BOXKU  
Boxed set of half round (Woodruff) keys NFE22179, Boxed set of half ...



BLHM40  
Right angled gearbox, double output shafts, up to 10.3 Nm



CAP805  
Slat top chain stainless steel, Large range 805



R205  
Die spring ISO10243, Heavy



J66  
Spur gear coaxial gearbox, from 0.90 to 2.80 Nm - Inline



D-PAR\_SS  
Stainless steel elasto mount, stainless steel



DP  
Dowel pin, Solid ISO 2338



HCSS  
Set screw with hexagonal socket, Cup point

## Complementary products



UCF\_SS  
Stainless steel flanged bearing, Stainless steel



UCFL\_SS  
Stainless steel flanged bearing, Stainless steel



BPPss  
Pressed stainless steel pillow block, Stainless steel