



Stainless steel pillow block bearing





2 mounting points

UCPss

- Self aligning bearing with 2 mounting points
- Interchangeable with cast iron units
- Working temperature range: until +140°C
- Materials:
 Bearing: stainless steel
 Housing: stainless steel

stainless steel

For hostile environments

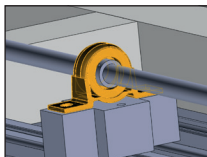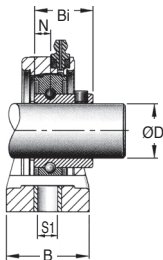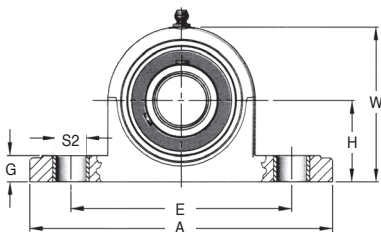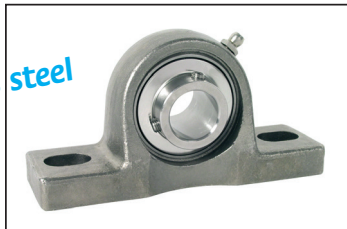

Typical application

DISCOUNTS

Qty	1+	10+	26+
Disc.	List -10%	On request	

Part number	ØD	H	A	E	B	S1	S2	G	W	Bi	N	Weight (kg)	Price each
													Stock*
UCP204/SS	20	33,3	127	95,0	38	13,0	19,0	13,0	65,0	31,0	12,7	0,70	✓ 53,12 €
UCP205/SS	25	36,5	140	105,0	38	13,0	19,0	15,0	71,0	34,1	14,3	0,85	✓ 58,67 €
UCP206/SS	30	42,9	165	121,0	48	17,0	20,0	17,0	84,0	38,1	15,9	1,20	✓ 82,74 €
UCP207/SS	35	47,6	167	127,0	48	17,0	19,0	19,0	93,0	42,9	17,5	1,70	✓ 116,28 €
UCP208/SS	40	49,2	184	137,0	54	17,0	20,0	20,0	98,0	49,2	19,0	2,10	✓ 134,80 €

*Depending on availability - Dimensions in mm

Our other products



 
KB_WW
Closed linear
precision bearing,
Economy range



UCP_PBT
Stainless/Polymer
pillow block bearing,
Polymer and stainless
steel



CCL
Standard wire
thimble, Steel



M0
Worm and wheel set,
Bronze



T5M_T10M
T type timing belt per
metre, T10 Steel
cored polyurethane



DBL820
Idler for slat top
chain, Ranges 820
and 815



SF_ZZ
Deep groove ball
bearing, Stainless
steel



RFVcap
Stainless steel
protective cover,
Open protective cover



 
VRM
Female swivelling
lifting rings, Female
swivelling



J65
Spur gear coaxial
gearbox, from 0.80 to
2.95 Nm - Inline



MEB
Moulded plastic bevel
gear (nylon), 1:1



PTR
Idler chain sprocket,
For standard
applications

Complementary products



UCF_SS
Stainless steel flanged
bearing, Stainless
steel



UCFL_SS
Stainless steel flanged
bearing, Stainless
steel



BPPss
Pressed stainless
steel pillow block,
Stainless steel