



Actuator guide kit

Coupling for threaded cylinder end

 
UGAC
UGET

UGAC: Connects the threaded end of the actuator to the piece to be moved

- In line flexible coupling, allows radial movement (E) of the cylinder end
- Material: Zinc plated steel



UGAC




UGET

Info.

- Grease the 2 surfaces (marked G) during assembly

UGET: For connecting the threaded end of a short stroke actuator to the UGAC coupling

- Material: Blackened steel, zinc plated steel

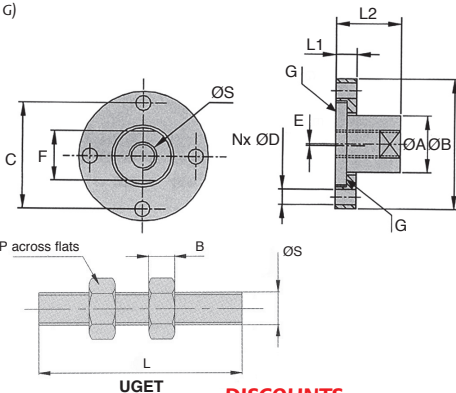

Info.

- If the actuator does not complete the stroke, check the tightness of the threads

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-5%	On request

Coupling for cylinder end

Part number	ØS	ØA	ØB	C	ØD	L1	L2	E	F	N	Weight (kg)	Price each
UGAC-6	M6	9	26	19	4,5	8	14	0,5	8	2	0,02	19,18 €
UGAC-8	M8	16	38	31	5,5	8	22	1,0	13	2	0,08	22,35 €
UGAC-10F	M10x1,25	16	38	31	5,5	8	22	1,0	13	2	0,08	22,35 €
UGAC-12F	M12x1,25	24	55	45	6,5	9	28	1,0	21	4	0,19	28,11 €
UGAC-16F	M16x1,5	24	55	45	6,5	9	28	1,0	21	4	0,19	28,11 €
UGAC-20F	M20x1,5	29	70	56	8,5	10	35	1,5	24	4	0,31	35,75 €
UGAC-27F	M27x2	39	100	76	13,0	16	43	1,5	32	4	0,90	65,66 €

Connector for threaded actuator rod

Part number	ØS	L	B	P	Price each
UGET-6	M6	40	4,8	10	3,62 €
UGET-8	M8	60	6,4	13	3,99 €


Dimensions in mm

Our other products




GPB55

 Threaded spherical knob, Aluminium



NK80

 Drylin@N miniature guiding system, Width 80mm




LWH

High rigidity linear slide, Chariot - from 9320 N to 71300 N



PRF-SMA

 Closing system for aluminium profile, Easily adjustable lock



B

Steel bevel gear, 1:1



DCA

Suction cup, 1.5 bellows, silicon



HK

Manual locking clamp, Manual locking clamp LWH



 
SLB

Indexing plunger, steel class 5.8



BDMdII

Magnetic bush for pin, Fast and light



CXS

External circlip DIN471, external DIN



GARDLL

Mounting sleeve for lock pin, Nickel-plated



CHAsb28

Roll of hinge without pin, Plastic hinge

Complementary products



UGPC

Actuator guide kit, Short bearing



UGCG

Actuator guide kit, Long housing