



 

UGCG

Guide shaft

- Allows the assembly of customised length actuator guides with 1-4 guide shafts
- For short or long bearings
- Material: Hardened ground steel XC55

Excellent price
Quality/ratio

Hardened steel

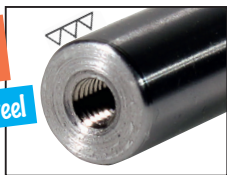

DISCOUNTS

| | | | |
|-------|----------|------------|----|
| Qty | 1+ | 2+ | 4+ |
| Disc. | List -5% | On request | |

| Part number | ØC (h6) | L (mm) | ØM1 | ØM2 | Weight (kg) | Price each |
|-------------|---------|--------|-----|-----|-------------|------------|
| UGCG10-127 | 10 | 127 | M5 | M5 | 0,08 | 24,29 € |
| UGCG10-152 | 10 | 152 | M5 | M5 | 0,09 | 25,01 € |
| UGCG10-177 | 10 | 177 | M5 | M5 | 0,11 | 25,79 € |
| UGCG10-227 | 10 | 227 | M5 | M5 | 0,14 | 27,26 € |
| UGCG10-277 | 10 | 277 | M5 | M5 | 0,17 | 28,77 € |
| UGCG10-327 | 10 | 327 | M5 | M5 | 0,20 | 30,24 € |
| UGCG12-164 | 12 | 164 | M5 | M6 | 0,15 | 26,66 € |
| UGCG12-189 | 12 | 189 | M5 | M6 | 0,17 | 27,64 € |
| UGCG12-239 | 12 | 239 | M5 | M6 | 0,21 | 29,52 € |
| UGCG12-299 | 12 | 299 | M5 | M6 | 0,27 | 31,81 € |
| UGCG12-339 | 12 | 339 | M5 | M6 | 0,30 | 33,32 € |
| UGCG12-389 | 12 | 389 | M5 | M6 | 0,35 | 35,21 € |
| UGCG12-459 | 12 | 459 | M5 | M6 | 0,41 | 37,89 € |
| UGCG16-182 | 16 | 182 | M6 | M6 | 0,29 | 32,84 € |
| UGCG16-207 | 16 | 207 | M6 | M6 | 0,32 | 34,03 € |
| UGCG16-257 | 16 | 257 | M6 | M6 | 0,40 | 36,42 € |
| UGCG16-317 | 16 | 317 | M6 | M6 | 0,50 | 39,25 € |
| UGCG16-357 | 16 | 357 | M6 | M6 | 0,56 | 41,20 € |
| UGCG16-407 | 16 | 407 | M6 | M6 | 0,64 | 43,54 € |
| UGCG16-477 | 16 | 477 | M6 | M6 | 0,75 | 46,88 € |
| UGCG16-557 | 16 | 557 | M6 | M6 | 0,87 | 50,70 € |
| UGCG20-232 | 20 | 232 | M8 | M8 | 0,57 | 37,75 € |
| UGCG20-282 | 20 | 282 | M8 | M8 | 0,69 | 40,47 € |
| UGCG20-342 | 20 | 342 | M8 | M8 | 0,84 | 43,72 € |
| UGCG20-382 | 20 | 382 | M8 | M8 | 0,94 | 45,92 € |
| UGCG20-432 | 20 | 432 | M8 | M8 | 1,06 | 48,62 € |
| UGCG20-502 | 20 | 502 | M8 | M8 | 1,23 | 52,46 € |
| UGCG20-582 | 20 | 582 | M8 | M8 | 1,43 | 56,82 € |
| UGCG20-682 | 20 | 682 | M8 | M8 | 1,67 | 62,27 € |
| UGCG25-286 | 25 | 286 | M10 | M10 | 1,10 | 49,83 € |
| UGCG25-336 | 25 | 336 | M10 | M10 | 1,29 | 53,10 € |
| UGCG25-396 | 25 | 396 | M10 | M10 | 1,52 | 56,98 € |
| UGCG25-436 | 25 | 436 | M10 | M10 | 1,67 | 59,87 € |
| UGCG25-486 | 25 | 486 | M10 | M10 | 1,86 | 62,83 € |
| UGCG25-556 | 25 | 556 | M10 | M10 | 2,13 | 67,42 € |
| UGCG25-636 | 25 | 636 | M10 | M10 | 2,44 | 72,62 € |
| UGCG25-736 | 25 | 736 | M10 | M10 | 2,82 | 79,13 € |

Dimensions in mm

Our other products



EPRF

High helix leadscrew,
Flanged nut - up to
40mm per rotation



PTGR

Tensioner pulley, For
round belts



PSG1HC

Skive hobbled spur
gears - precision
range, Case hardened
steel 20NCD2



PARF80

Pressed steel base
rigid foot, Swivelling -
Ø80



ES

Bipod support base,
Plastic



P70

Worm and wheel gear
reducer, up to 164
Nm



G-ECO

Eco range Spur gear,
Steel C45



PTA50

Articulated levelling
foot, pressed base
Ø50, 4000N



SSB

Stainless steel bevel
gear, 1:1



MPB

Hexagonal spacer,
Brass



TTBSS

Stainless steel axial
thrust bearing,
Stainless steel



BOXKU

Boxed set of half
round (Woodruff) keys
NFE22179, Boxed set
of half ...

Complementary products



UGPC

Actuator guide kit,
Short bearing



UGPL

Actuator guide kit,
Long bearing



ZAmM

Shaft for linear
guides, Hardened
ground steel



ZA

Shaft for linear
guides, Hardened
ground steel