

# Actuator guide kit



 

## UGCG

## Guide shaft

- Allows the assembly of customised length actuator guides with 1-4 guide shafts
- For short or long bearings
- Material: Hardened ground steel XC55

Excellent price  
Quality/ratio

Hardened steel

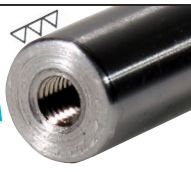

### DISCOUNTS

Qty	1+	2+	4+
Disc.	List -5%	On request	

Part number	ØC (h6)	L (mm)	ØM1	ØM2	Weight (kg)	Price each
UGCG10-127	10	127	M5	M5	0,08	24,29 €
UGCG10-152	10	152	M5	M5	0,09	25,01 €
UGCG10-177	10	177	M5	M5	0,11	25,79 €
UGCG10-227	10	227	M5	M5	0,14	27,26 €
UGCG10-277	10	277	M5	M5	0,17	28,77 €
UGCG10-327	10	327	M5	M5	0,20	30,24 €
UGCG12-164	12	164	M5	M6	0,15	26,66 €
UGCG12-189	12	189	M5	M6	0,17	27,64 €
UGCG12-239	12	239	M5	M6	0,21	29,52 €
UGCG12-299	12	299	M5	M6	0,27	31,81 €
UGCG12-339	12	339	M5	M6	0,30	33,32 €
UGCG12-389	12	389	M5	M6	0,35	35,21 €
UGCG12-459	12	459	M5	M6	0,41	37,89 €
UGCG16-182	16	182	M6	M6	0,29	32,84 €
UGCG16-207	16	207	M6	M6	0,32	34,03 €
UGCG16-257	16	257	M6	M6	0,40	36,42 €
UGCG16-317	16	317	M6	M6	0,50	39,25 €
UGCG16-357	16	357	M6	M6	0,56	41,20 €
UGCG16-407	16	407	M6	M6	0,64	43,54 €
UGCG16-477	16	477	M6	M6	0,75	46,88 €
UGCG16-557	16	557	M6	M6	0,87	50,70 €
UGCG20-232	20	232	M8	M8	0,57	37,75 €
UGCG20-282	20	282	M8	M8	0,69	40,47 €
UGCG20-342	20	342	M8	M8	0,84	43,72 €
UGCG20-382	20	382	M8	M8	0,94	45,92 €
UGCG20-432	20	432	M8	M8	1,06	48,62 €
UGCG20-502	20	502	M8	M8	1,23	52,46 €
UGCG20-582	20	582	M8	M8	1,43	56,82 €
UGCG20-682	20	682	M8	M8	1,67	62,27 €
UGCG25-286	25	286	M10	M10	1,10	49,83 €
UGCG25-336	25	336	M10	M10	1,29	53,10 €
UGCG25-396	25	396	M10	M10	1,52	56,98 €
UGCG25-436	25	436	M10	M10	1,67	59,87 €
UGCG25-486	25	486	M10	M10	1,86	62,83 €
UGCG25-556	25	556	M10	M10	2,13	67,42 €
UGCG25-636	25	636	M10	M10	2,44	72,62 €
UGCG25-736	25	736	M10	M10	2,82	79,13 €

Dimensions in mm

## Our other products



MBF

Threaded blocking clamp, Threaded locking clamp



HCA

Magnetic screw with socket, Steel



CAP882

Flexible slat top chain acetal, Large range 882



BH01

Single housed bearing, Bearing fitted with adhesive



VPR

Wing screw Hygienic Usit®, Stainless steel



PO

Pull handle - Multi-sector, Tapped recessed insert



TSRTC

Stem support for caster, For swivel caster with central hole



CHA\_GC\_14SS

Stainless steel garnet hinge, To screw



SLV

Vertical toggle clamp, Vertical Lever Clamp - stainless steel



SHW

Plain washer, A2 Stainless steel



SSG1

Stainless steel spur gear, Stainless steel 304L



BSCf

Knurled torque knobs - female, Knurled threaded torque

## Complementary products



UGPC

Actuator guide kit, Short bearing



UGPL

Actuator guide kit, Long bearing



ZAm

Shaft for linear guides, Hardened ground steel



ZA

Shaft for linear guides, Hardened ground steel