

Actuator guide kit



 

UGCG

Guide shaft

- Allows the assembly of customised length actuator guides with 1-4 guide shafts
- For short or long bearings
- Material: Hardened ground steel XC55

Excellent price
Quality/ratio

Hardened steel

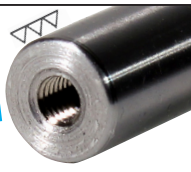

DISCOUNTS

Qty	1+	2+	4+
Disc.	List -5%		On request


Part number	ØC (h6)	L (mm)	ØM1	ØM2	Weight (kg)	Price each
UGCG10-127	10	127	M5	M5	0,08	24,29 €
UGCG10-152	10	152	M5	M5	0,09	25,01 €
UGCG10-177	10	177	M5	M5	0,11	25,79 €
UGCG10-227	10	227	M5	M5	0,14	27,26 €
UGCG10-277	10	277	M5	M5	0,17	28,77 €
UGCG10-327	10	327	M5	M5	0,20	30,24 €
UGCG12-164	12	164	M5	M6	0,15	26,66 €
UGCG12-189	12	189	M5	M6	0,17	27,64 €
UGCG12-239	12	239	M5	M6	0,21	29,52 €
UGCG12-299	12	299	M5	M6	0,27	31,81 €
UGCG12-339	12	339	M5	M6	0,30	33,32 €
UGCG12-389	12	389	M5	M6	0,35	35,21 €
UGCG12-459	12	459	M5	M6	0,41	37,89 €
UGCG16-182	16	182	M6	M6	0,29	32,84 €
UGCG16-207	16	207	M6	M6	0,32	34,03 €
UGCG16-257	16	257	M6	M6	0,40	36,42 €
UGCG16-317	16	317	M6	M6	0,50	39,25 €
UGCG16-357	16	357	M6	M6	0,56	41,20 €
UGCG16-407	16	407	M6	M6	0,64	43,54 €
UGCG16-477	16	477	M6	M6	0,75	46,88 €
UGCG16-557	16	557	M6	M6	0,87	50,70 €
UGCG20-232	20	232	M8	M8	0,57	37,75 €
UGCG20-282	20	282	M8	M8	0,69	40,47 €
UGCG20-342	20	342	M8	M8	0,84	43,72 €
UGCG20-382	20	382	M8	M8	0,94	45,92 €
UGCG20-432	20	432	M8	M8	1,06	48,62 €
UGCG20-502	20	502	M8	M8	1,23	52,46 €
UGCG20-582	20	582	M8	M8	1,43	56,82 €
UGCG20-682	20	682	M8	M8	1,67	62,27 €
UGCG25-286	25	286	M10	M10	1,10	49,83 €
UGCG25-336	25	336	M10	M10	1,29	53,10 €
UGCG25-396	25	396	M10	M10	1,52	56,98 €
UGCG25-436	25	436	M10	M10	1,67	59,87 €
UGCG25-486	25	486	M10	M10	1,86	62,83 €
UGCG25-556	25	556	M10	M10	2,13	67,42 €
UGCG25-636	25	636	M10	M10	2,44	72,62 €
UGCG25-736	25	736	M10	M10	2,82	79,13 €

Dimensions in mm

Our other products



 TOC
Short swivel head,
Short



AC
Strike for toggle latch,
18mm



STRIP1000
Sealing brush strip,
1m length



ATZYSS
Stainless steel diabolo
shaped elasto mount,
Stainless steel



 
H3
Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



MDB_MTB
Moulded plastic bevel
gear (nylon), 2:1



RGS
Rotex® GS backlash
free jaw coupling,
from 0.5 to 190Nm



M1
Worm and wheel set,
Machined plastic
(delrin)



PRES3HR
Manual workbench
press, Force up to
400kg



LFM2
Steel leadscrew,
Medium carbon steel -
2 threads



SH0
Parallel axis helical
gear, Steel 20NCD2



SEH
Horizontal stirrup
toggle clamp,
Horizontal Latch
clamp - stainless ...

Complementary products



UGPC
Actuator guide kit,
Short bearing



UGPL
Actuator guide kit,
Long bearing



ZAmM
Shaft for linear
guides, Hardened
ground steel



ZA
Shaft for linear
guides, Hardened
ground steel